

# Datasheet

667-3935

Description: Metric Dial Caliper

Specification: 0-200mm

Resolution: 0.02mm

Accuracy:  $\pm 0.03\text{mm}$



## FEATURES

The slider is covered to seal out dirt and grease.

Dial caliper measures four ways: ID, OD, Depth&Step.


Accuracy can change: 0.001" and 0.02mm.

Zero can be quickly and easily reset.

Dial caliper shockproof system protects its gear mechanism.

Rugged stainless steel construction and satin chrome finish for long life.

Fitted plastic case.

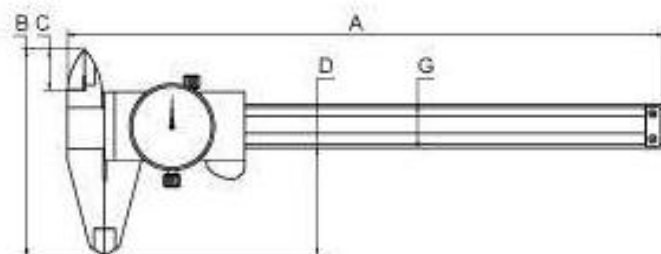

## Dimensions

Range	A	B	C	D	G
0-100mm/0-4"	160mm	60mm	12.5mm	30mm	13mm
0-150mm/0-6"	234mm	77mm	16mm	40mm	16mm
0-200mm/0-8"	290mm	90.5mm	19mm	50mm	17mm