


FAST SANDING OF PAINT AND WOOD

EXPERT C470 Sandpaper

EXPERT

- ① Exceptional abrasion with Bosch Surface Structure
- ② Grain alignment during production ensures aggressive cut
- ③ Grain distribution optimised for high-speed sanding

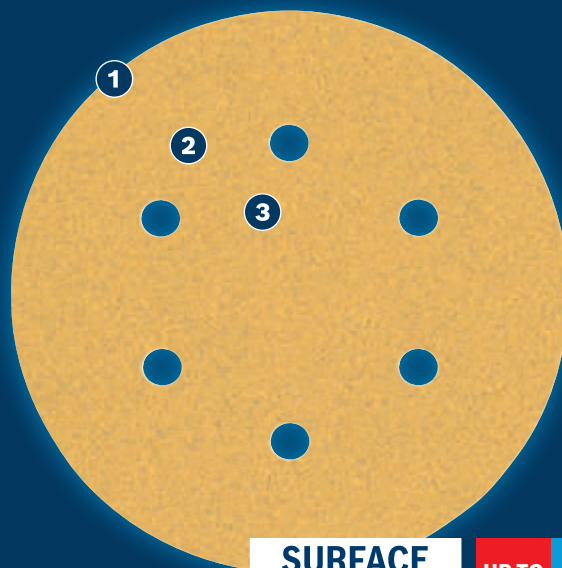

SURFACE
STRUCTURE

UP TO
2x*



* vs. Bosch C420




Video



BOSCH

EXPERT C470 SANDING DISCS

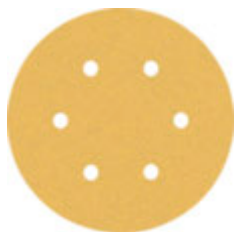

- ▶ Ideal for highly effective fast sanding of flat surfaces; to remove old paint; or to smooth, prepare and finish surfaces
- ▶ EXPERT Abrasives - the very best for all trades
- ▶ Up to 2x faster than Bosch C420 Sandpaper
- ▶ Just stick it on with hook and loop



PRODUCT PROPERTIES				ORDERING INFORMATION					
Disc diameter mm	Grit	Perforation	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	Part number		
150	40	6 holes	C1a	5	5	541 518	2 608 900 813		
150	60	6 holes	C1a	5	5	541 525	2 608 900 814		
150	80	6 holes	C1a	5	5	541 532	2 608 900 815		
150	100	6 holes	C1a	5	5	541 549	2 608 900 816		
150	120	6 holes	C1a	5	5	541 556	2 608 900 817		
150	180	6 holes	C1a	5	5	541 563	2 608 900 818		
150	240	6 holes	C1a	5	5	541 570	2 608 900 819		
150	320	6 holes	C1a	5	5	541 587	2 608 900 820		
150	400	6 holes	C1a	5	5	541 594	2 608 900 821		
150	40	6 holes	C0a	50	1	542 553	2 608 900 917		
150	60	6 holes	C0a	50	1	542 560	2 608 900 918		
150	80	6 holes	C0a	50	1	542 577	2 608 900 919		
150	100	6 holes	C0a	50	1	542 584	2 608 900 920		
150	120	6 holes	C0a	50	1	542 591	2 608 900 921		
150	150	6 holes	C0a	50	1	544 601	2 608 901 122		
150	180	6 holes	C0a	50	1	542 607	2 608 900 922		
150	220	6 holes	C0a	50	1	544 618	2 608 901 123		
150	240	6 holes	C0a	50	1	542 614	2 608 900 923		
150	320	6 holes	C0a	50	1	542 621	2 608 900 924		
150	400	6 holes	C0a	50	1	542 638	2 608 900 925		



BOSCH