

PRODUCT DATASHEET

P CLAS A 150 19 W/2700K E27

PARATHOM CLASSIC A | LED lamps, classic bulb shape



AREAS OF APPLICATION

- Domestic applications
- General illumination
- Outdoor use in outdoor luminaires only (minimum IP65)

PRODUCT BENEFITS

- Low energy consumption
- Easy replacement of classic lamps thanks to compact design
- Instant 100 % light, no warm-up time

PRODUCT FEATURES

- Professional LED lamps for line voltage
- Not dimmable
- Lifetime: up to 15,000 h
- Good quality of light; color rendering index $R_a \geq 80$; constant chromaticity



TECHNICAL DATA

Electrical data

Rated wattage	19.00 W
Nominal wattage	19.00 W
Nominal voltage	220...240 V
Max. lamp no. on circuit break. 10 A (B)	29
Max. lamp no. on circuit break. 16 A (B)	48
Operating frequency	50...60 Hz
Power factor λ	> 0.50
Claimed equiv. conventional lamp power	150 W


Photometrical data

Nominal luminous flux	2452 lm
Rated luminous flux	2452 lm
Lumen main.fact.at end of nom.life time	0.70
Light color (designation)	Warm White
Color temperature	2700 K
Luminous flux	2452 lm
Color rendering index Ra	≥ 80
Standard deviation of color matching	≤ 6 sdc _m
Rated color temperature	2700 K
Color rendering index Ra	≥ 80

Light technical data

Warm-up time (60 %)	< 1.00 s
Starting time	< 0.5 s

Dimensions & weight

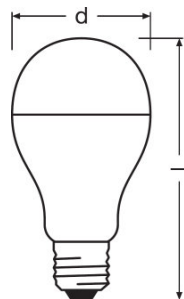

Overall length	128.0 mm
----------------	----------

Diameter	68.0 mm
Outer bulb	A67
Length	128.0 mm

Temperatures & operating conditions

Ambient temperature range	-15...+40 °C
Maximum temperature at tc test point	100 °C

Lifespan

Nominal lamp life time	15000 h
Rated lamp life time	15000 h
Number of switching cycles	100000
Lumen maintenance at end of service life	0.70

Additional product data

Base (standard designation)	E27
Mercury content	0.0 mg
Mercury-free	Yes
Design / version	frosted
Show WEEE picto	Yes
Product remark	All technical parameters apply to the entire lamp/Due to the complex production process for light-emitting diodes, the typical values shown for the technical LED parameters are purely statistical values that do not necessarily match the actual technical parameters of each individual product, which can vary from the typical value

Capabilities

Dimmable	No
-----------------	----

Certificates & standards

Energy efficiency class	A++
Energy consumption	19 kWh/1000h

Country-specific categorizations

Order reference	LEDPCLA150 19W/
------------------------	-----------------

LOGISTICAL DATA

Product code	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Gross weight	Volume
4058075463127	Folding carton box 1	71 mm x 71 mm x 135 mm	86.00 g	0.68 dm ³

4058075463134	Shipping carton box 10	366 mm x 151 mm x 150 mm	1021.00 g	8.29 dm ³
---------------	---------------------------	--------------------------	-----------	----------------------

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

REFERENCES / LINKS

For further products and actual information concerning LED lamps see

▶ www.ledvance.com/ledlamps

For Guarantee see

▶ www.ledvance.com/guarantee

DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.