


Wirable socket

SDOGF030MSSFKPG

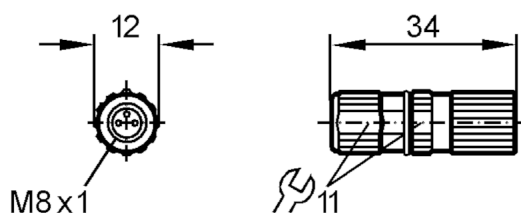

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 45 AC / < 70 DC

Protection class

III

Max. current load total

[A]

4

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 68

Mechanical data

Weight

[g]

17.2

Materials

Core insulation: PVC / TPE

Moulded-body material

PA

Material nut

brass, nickel-plated

Remarks

Pack quantity

1 pcs.

E11552



Wirable socket

SDOGF030MSSFKPG

Electrical connection

insulation displacement technology: 0.14...0.38 mm²; Core insulation: PVC / TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

