



Datasheet

RS PRO 2m D25 Way M to D25 Way female Straight Through Cable


Stock number: 182-8823

EN

Our RS PRO 2m D25 male to D25 female is wire pin to pin has a beige PVC cable flex.

The connector hoods are made from beige PVC and have a strain relief on the end of the hood to support the cable and to stop the cable from splitting around the hood.

The cable flex has an outer diameter of 7mm and 28awg, the connectors have gold flash pins to help stop corrosion.

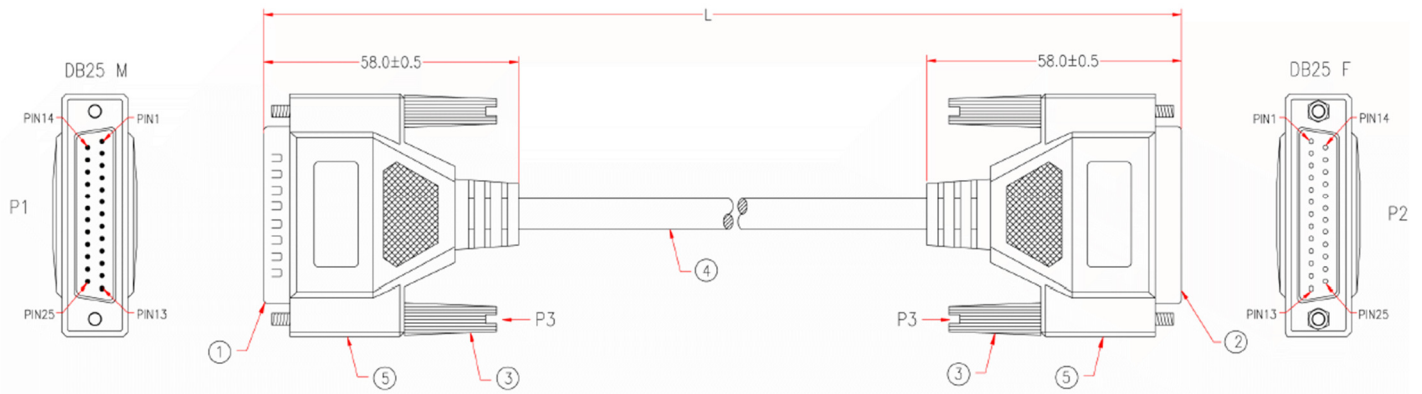

P1	P2	P1	P2
BROWN	1	14	14
RED	2	15	15
ORANGE	3	16	16
PINK	4	17	17
YELLOW	5	18	18
GREEN	6	19	19
LIGHT GREEN	7	20	20
BLUE	8	21	21
LIGHT BLUE	9	22	22
PURPLE	10	23	23
GREY	11	24	24
WHITE	12	25	25
BLACK	13	SHIELD	SHIELD

5	BLACK PVC TUBE $\varnothing 3.0 \times 30\text{mm}$
	ALUMINUM FOIL 33*110mm
	MOLDED PE COLOR TRANSPARENT
4	MOLDED PVC BEIGE
	NON-UL 25C 30AWG, ALUM-MYLAR FOIL SHIELDING WITH DRAIN WIRE, OD 7.0mm, JACKET BEIGE
3	MOLDED THUMBSCREW #4-40, LENGTH 46.5mm, BEIGE
2	DB25 FEMALE, GOLD FLASH ON CONTACTS, BLUE INSULATOR
1	DB25 MALE, GOLD FLASH ON CONTACTS, BLUE INSULATOR

RoHS / REACH / CE

rspro.com