



Envision all you can do

DELL ULTRASHARP 38 CURVED MONITOR | U3818DW



BE INSPIRED TO DO MORE

All-encompassing.
Virtually borderless curved screen.



CONSISTENT COLOR. INCREDIBLE DETAIL.

Enjoy stunning visuals with sharp details.



MULTITASK LIKE A PRO

Productivity features for multitasking efficiency.




HIGHLY RELIABLE

World's number 1 monitor company.*

Envision all you can do

DELL ULTRASHARP 38 CURVED MONITOR | U3818DW

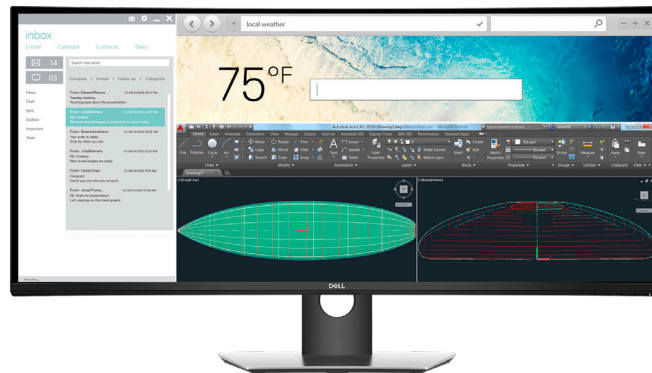

YOU'LL BE INSPIRED TO DO MORE

Get an immersive experience and enjoy incredible visuals on this 37.5" WQHD+ curved screen with InfinityEdge.

- **Stay focused on your work:** The curvature of this expansive screen creates a near-complete field of view, providing an almost uniform visual focus that reduces eye movement across the screen. You'll work more comfortably with fewer distractions and more productivity.
- **Gorgeous visuals are only the beginning:** This 37.5" WQHD+ (3840 x 1600) curved screen delivers approximately 25 percent more screen content than a 34" screen. Plus InfinityEdge offers a virtually borderless display.
- **All-encompassing experience:** This curved screen with 21:9 aspect ratio delivers a panoramic viewing experience while integrated 9W speakers bring the quality sound — a one-two punch that makes this monitor the ideal canvas for video editing projects.

CONSISTENT COLOR. INCREDIBLE DETAIL.

Complete your work projects and enjoy home entertainment with vivid visuals, accurate color and sharp details.

- **More show than tell:** You can expect outstanding detail and consistent color across a wide viewing angle — WQHD+ (3840 x 1600) screen featuring In-Plane Switching technology.
- **Accurate color, right out of the box:** Your monitor comes with 99% sRGB factory calibration for impressively precise color at Delta-E less than 2.

MULTITASK LIKE A PRO

Now you have the screen space, the tools and the features you need to do everything efficiently.

- **Get it done:** With features like Dell Easy Arrange, you can arrange your projects to best suit your screen space, while the Picture-in-Picture and Picture-by-picture (PbP) features allow you to display content from two PC sources simultaneously.
- **Masterful manageability:** You can display and edit content from two different PCs with a single KVM feature (keyboard, video and mouse).
- **Convenient connectivity:** A single cable solution with a USB Type-C connectivity transmits power, audio and video signals between a laptop and monitor. Connect and charge from a single source while reducing cable clutter.
- **Easy on the eyes:** This TUV-Certified¹ monitor has a flicker-free screen with ComfortView, a feature that filters harmful blue light emissions to optimize eye comfort.

SUPERB RELIABILITY

Comes with Dell's high reliability promise.

- Dell monitors are #1 worldwide for 6 consecutive years (2013 to 2019)!*
- Enjoy peace of mind with Dell's Premium Panel Exchange².
- Minimize downtime with Dell's Advanced Exchange Service.³
- Upgrade to 24x7 specialized technical phone support with the Dell ProSupport option.⁶

For more information
visit Dell.com/monitors



Thank you
for making
Dell Monitors
#1
worldwide*

Features & Technical Specifications

DELL ULTRASHARP 38 CURVED MONITOR | U3818DW

Display

Model number	U3818DW
Viewable image size (diagonal)	95.3 cm (37.5 inches)
Active display area	
Horizontal	879.67 mm (34.63 inches)
Vertical	366.53 mm (14.43 inches)
Maximum resolution	3840 x 1600 at 60Hz (WQHD+)
Curve radius	2300R
Aspect ratio	21:9
Pixel pitch	0.229 mm x 0.229 mm
Pixels per inch (PPI)	111
Brightness (typical)	300 cd/m ²
Color gamut (typical)	99% sRGB at Delta-E < 2 (average), 99% Rec. 709, 78.1% DCI-P3
Color depth	1.07 billion colors
Contrast ratio (typical)	1000: 1 (typical)
Viewing angle (typical) (vertical/horizontal)	178°/178°
Response time	5ms (gray to gray) fast mode; 8ms normal mode
Panel technology	In-Plane Switching type; Anti-glare with (3H) hard coating
Backlight	LED edgelight system
ComfortView with Flicker-free screen	Yes
Dell Display Manager	Yes with Dell Easy Arrange and other key features
Remote asset management	Yes, via Dell Command/Monitor
Integrated speakers	2 x 9W speakers

Connectivity

Connectors	1 x DP 1.2 (HDCP 2.2), 2 x HDMI 2.0 (HDCP 2.2), 2 x USB 3.0 upstream port, 2 x USB 3.0 Downstream port (side), 2 x USB 3.0 Downstream port (bottom), 1 x USB Type-C (Alternate mode with DP1.2, Power Delivery of up to 100W, and USB 2.0), 1 x Analog 2.0 audio line out (3.5 mm jack)
Built-in devices	USB 3.0 Hi-Speed Hub with KVM feature (2 x USB upstream port and 4 x USB downstream, with 2 x BC1.2 charging capability at 2A (max); USB Type-C (Alternate mode with DP1.2, Power Delivery of up to 100W, and USB 2.0)

Design features

Stand	Height adjustable (up to 115mm), Tilt (-5°/21°), Swivel (-30° to 30°), Built in cable-management
Security	Security lock slot (security lock not included), anti-theft stand lock slot (to panel)
VESA mounting support	100 mm x 100 mm

Power

AC input voltage/frequency/current	100 VAC to 240 VAC / 50 Hz or 60 Hz + 3 Hz / 3 A (typical)
Power consumption (typical)	56W
Power consumption (standby/sleep mode)	<0.3W

Dimensions (with stand)

Height (compressed~extended)	432.0 mm ~ 547.0 mm (17.00 inches ~ 21.54 inches)
Width	894.0 mm (35.2 inches)
Depth	226.4 mm (8.91 inches)

Weight

Weight (panel only)	9.05 kg (19.95 lb)
Weight (with stand)	12.14 kg (26.76 lb)
Shipping weight	19.7 kg (43.42 lb)

Standard service plan

3 Years Advanced Exchange Service³ & Limited Hardware Warranty⁴, Premium Panel Exchange²

Environmental compliance

RoHS Compliant, Arsenic-Free glass and Mercury-Free for the panel only.

What's in the box?

Components

- Monitor with stand

Cables

- HDMI cable
- DisplayPort cable
- USB 3.0 upstream cable
- USB Type-C cable
- Power cable


Documentation

- Quick Setup Guide
- Safety and regulatory information
- Factory Calibration Report


Adjustability and connectivity

DELL ULTRASHARP 38 CURVED MONITOR | U3818DW

Easily adjust the panel to your preferred viewing position.

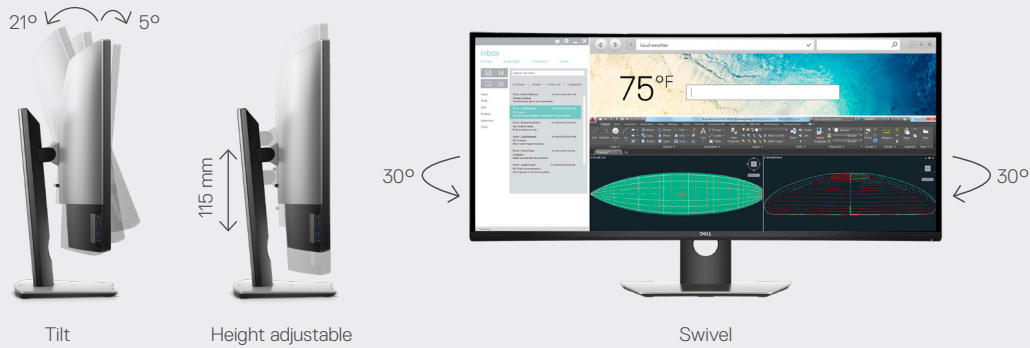

Connectivity

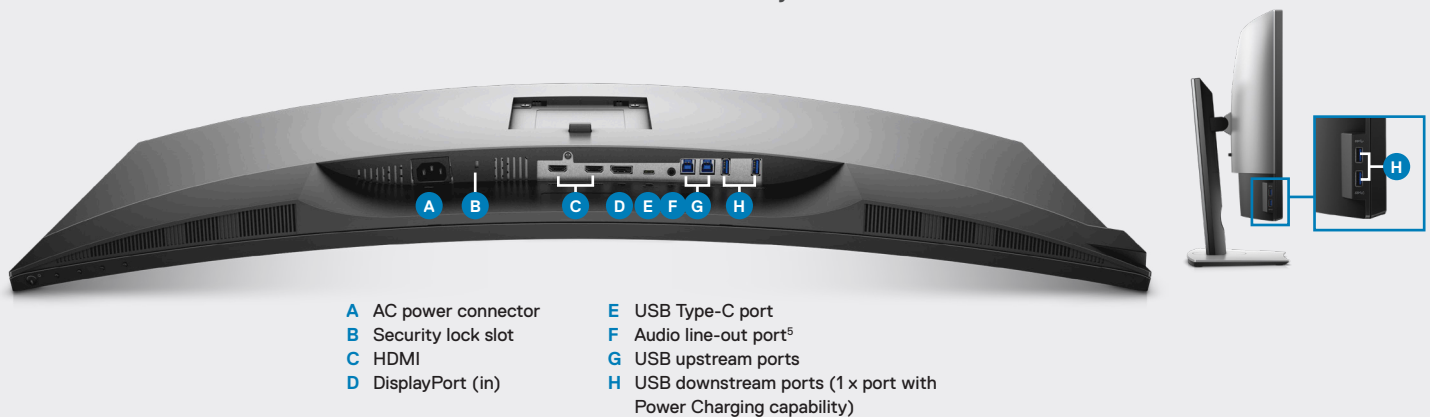

* Source: IDC Worldwide Quarterly PC Monitor Tracker, Q2 2019.

1 TUV Certified (ID0000051369 – Flicker Free / ID0000051370 – Low Blue Light Content). For more details, visit www.tuv.com.

2 The Dell Premium Panel Exchange allows a free monitor replacement during the Limited Hardware Warranty period even if only one bright pixel is found.

3 Advanced Exchange Service: Replacement part/unit dispatched, if needed, following completion of phone/online diagnosis. Fee charged for failure to return defective unit. Availability varies. Other conditions apply.

4 For a copy of the Limited Hardware Warranty, write Dell USA LP, Attn: Warranties, One Dell Way, Round Rock, TX 78682 or see Dell.com/warranty.

5 The audio line-out port does not support headphones and Dell soundbar.

6 Availability varies, please visit www.dell.com/support for details. In some countries, hours for in-region support may vary. Support after local business hours may be provided in a language other than the local language.