




ENGLISH

Datasheet

Stock No: 522-597

RS Pro SY Control Cable, 6 Core, Polyvinyl Chloride PVC Sheath

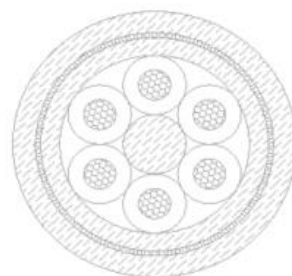

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): $0.25 \pm 0.008 \times 30$

Insulation: PVC

Insulation Dia. (mm): $2.8 \pm 0.1 \times 6C$

Filler 1: 2.8 PVC Strip

Filler 2: Chalk

Jacket 1: PVC

Outer Dia. (mm): 9.3 ± 0.25

Armour: Galvanised Steel

Conductor Dia. (mm): 0.24

Conductor Qty: 24x4

Jacket 2: Trans PVC

Outer Dia. (mm): 12.58 ± 0.3

Colour:

The colour of the insulation: Black x 5 ,

Yellow/Green

The jacket colour: Transparent

Marking(3times/m):

RS 522597 SY/NR 6 Core x 1.5mm²

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Performance:

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) :
<13.7

Min.Insulation DC Resistance at 20°C (MΩ*KM) :
>500

Current Rating : 16 A