
	Art.	L mm	Ø max "	Ø max mm	A mm	S mm	W g
003620020	362 200	200	1" gas	34	17	14	369
003620025	362 250	250	1"1/2 gas	49	22	17	842
003620030	362 300	300	2" gas	60	23	21	1187
003620035	362 350	350	2" gas	60	26	21	1279
003620045	362 450	450	2"1/2 gas	76	29	26	2580
003620060	362 600	600	3" gas	90	33	28	4045
003620090	362 900	900	5" gas	140	35	30	9000

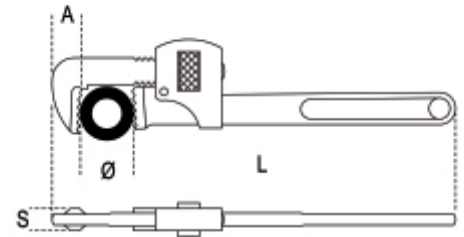

Scan the QR Code to access the web tab
 Specs, media and documentation in one click.

