

Accessories

Connectors and cables

Connection cable M12, 8-pin, straight, shielded



Features

- Connection cable shielded with female connector M12, shielding on cap nut
- 8-pin version
- Cable coating PUR
- Halogen-free
- Suitable for flexible cable carriers
- UL listed, number E315836
- Temperature -40...+80 °C (fixed installation)

Part number


10127844	Connection cable 2 m shielded with female connector M12, 8-pin, straight (ESG 34FH0200G)
10129332	Connection cable 5 m shielded with female connector M12, 8-pin, straight (ESG 34FH0500G)
10129333	Connection cable 10 m shielded with female connector M12, 8-pin, straight (ESG 34FH1000G)

Suitable for

EIL580 - blind hollow shaft, EIL580 - clamping flange, EIL580 - synchro flange, EIL580 - through hollow shaft, EIL580P - blind hollow shaft, EIL580P - clamping flange, EIL580P - synchro flange, EIL580P - through hollow shaft

Terminal assignment

Female connector M12	Core colour
Pin 1	white
Pin 2	brown
Pin 3	green
Pin 4	yellow
Pin 5	grey
Pin 6	pink
Pin 7	blue
Pin 8	red
Connector Housing	Shield/Housing

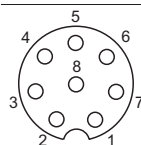

Dimensions

