


PHE 30GCRSB

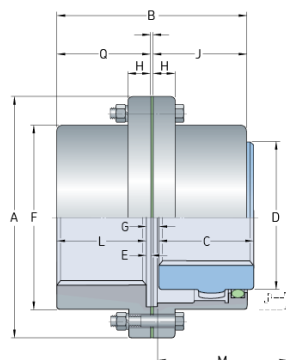

Size	30 GC
Power per 100 r/min (kW)	127
Power per 100 r/min (HP)	170.24
Rated torque (Nm)	12100
Rated torque (lbft)	8924.5
Speed Max. (r/min)	4400
Bore diameter Min. (mm)	39
Bore diameter Min. (in)	1.54
Bore diameter Max. (mm)	111
Bore diameter Max. (in)	4.37
A (mm)	240
A (in)	9.45
B (mm)	187
B (in)	7.36
C (mm)	91
C (in)	3.58
D (mm)	152
D (in)	5.98
F (mm)	180
F (in)	7.09
H (mm)	21.8
H (in)	0.86
J (mm)	84
J (in)	3.31

© SKF is a registered trademark of the SKF Group

© SKF Group 2012

The contents of this publication are the copyright of the publisher and may not be reproduced (even extracts) unless prior written permission is granted. Every care has been taken to ensure the accuracy of the information contained in this publication but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.

M (mm)	107
M (in)	4.21
Gap G Min. (mm)	5
Gap G Min. (in)	0.2
Lubricant mass (kg)	0.36
Lubricant mass (lbs)	0.79
Coupling mass without bore and min. DBSE (kg)	43
Coupling mass without bore and min. DBSE (lbs)	94.8

© SKF is a registered trademark of the SKF Group

© SKF Group 2012

The contents of this publication are the copyright of the publisher and may not be reproduced (even extracts) unless prior written permission is granted. Every care has been taken to ensure the accuracy of the information contained in this publication but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.

