


Type	Size	Rating	Description	Part No.
Incandescent	T6	6.3V 0.2A	T-1¾ Beadseal Lamp	2181BS

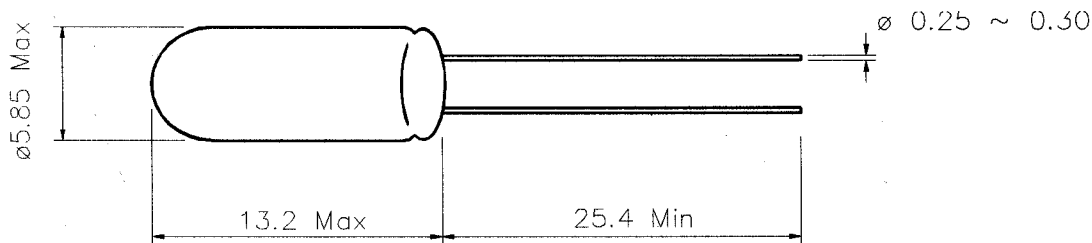

Drawing Not To Scale
All Dimensions In mm

PHOTOMETRY DATA

TEST VOLTS	CURRENT (mA)			LIGHT OUTPUT (Lm)			LIFE (Hours)
	Min.	Nom.	Max.	Min.	Nom.	Max.	
6.3	180	200	220	3.7	5.0	6.3	20,000

- NOTES:
- 1) C-2F filament shape.
 - 2) Lead wires 0.25mm diameter x 25.4mm MIN. long, with tinned finish.
 - 3) Other lead wire lengths to be supplied according to the purchase order.