

<b>Universe</b>	Professional
<b>Type</b>	Verticality
<b>Category</b>	Harnesses
<b>Subcategory</b>	Harnesses for fall arrest, work positioning and suspension




## AVAO® BOD FAST European version

The AVAO BOD FAST fall arrest, work positioning and suspension harness is designed for greater comfort in a variety of situations. Wide, semi-rigid waistbelt and leg loops give excellent support. Its lightweight, breathable construction maximizes air flow. The shoulder straps have a system for stowing the fall arrest lanyard connectors and keeping them within reach. The DOUBLEBACK self-locking buckles at the rear of the harness, between the waistbelt and the leg loops, allow for a shorter adjustment when the dorsal attachment point is used. The harness also facilitates the carrying and organizing of work tools, with multiple equipment loops and retainers for attaching CARITool tool holders and TOOLBAG tool-holder pouches. The harness is fastened by a SCREW-LOCK manual locking carabiner and is certified to European and Russian standards. The AVAO BOD FAST features leg loops with FAST LT automatic buckles.



Wide, semi-rigid waistbelt and leg loops give excellent support. Its lightweight, breathable construction maximizes air flow.

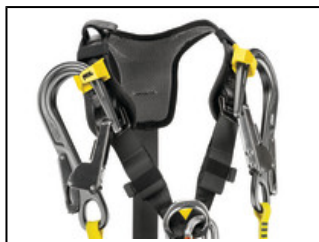

The MGO connectors on fall arrest lanyards can be stowed on each shoulder strap. The user is thus unhindered by the lanyard, and the connectors stay within reach. In case of a fall, the system releases the MGOs and allows the absorber to be deployed.



Waistbelt and leg loops equipped with self-locking DOUBLEBACK buckles which allow quick and easy adjustment.



Leg loops are equipped with FAST LT automatic buckles for quick and easy opening and fastening without the need to readjust them, even while wearing gloves.

---

**Short Description** Comfortable harness for fall arrest, work positioning and suspension

---

**Selling Points**





- Comfortable throughout the workday:
  - wide, semi-rigid waistbelt and leg loops for excellent support. Its lightweight, breathable construction maximizes air flow
  - foam shoulder straps are widely spaced to reduce neck chafing. When the waistbelt is loaded, they help distribute the load over the shoulders
- Convenient adjustment:
  - waistbelt and shoulder straps equipped with self-locking DOUBLEBACK buckles for quick and easy adjustment
  - leg loops equipped with FAST LT buckles for quick and easy opening and fastening without the need to readjust them, even while wearing gloves
  - stowage system for the MGO connectors on fall arrest lanyards, on each shoulder strap, allows the user to be unhindered by the lanyard and to keep the connectors within reach. In case of a fall, the system releases the MGO connectors and allows the absorber to be deployed
  - side attachment points can be folded down to prevent them snagging accidentally when not in use
  - DOUBLEBACK self-locking buckles at the rear of the harness, between the waistbelt and the leg loops, allow adjustment for use on the dorsal attachment point. In case of a fall on this point, a shorter adjustment allows the weight to be taken up on the leg loops so the user can remain more comfortably suspended while awaiting rescue.
- Facilitates the carrying and organization of tools:
  - six pre-shaped equipment loops with protective sheath
  - two slots for CARITool tool holder
  - four slots for TOOLBAG tool pouch



---

**Specification**

- Ventral attachment point: attachment for a descender or a positioning lanyard for use in single mode
  - Lateral attachment points: attachment for a positioning lanyard for use in double mode
  - Sternal attachment point: fall arrest system attachment
  - Dorsal attachment point: fall arrest system attachment
  - Rear attachment point on the waistbelt: restraint lanyard attachment
  - Certification(s): CE EN 361, CE EN 358, CE EN 813, EAC
  - Material(s): nylon, polyester, aluminum, steel
-

Specifications by reference

Reference(s)	C071BA00	C071BA01	C071BA02	C071BA03
				
Color(s)	black/yellow	black/yellow	black/yellow	black
Size	0	1	2	0
Waist belt	65-80 cm	70-93 cm	83-120 cm	65-80 cm
Leg loops	44-59 cm	47-62 cm	50-65 cm	44-59 cm
Stature	160-180 cm	165-185 cm	175-200 cm	160-180 cm
Weight	2000 g	2045 g	2125 g	2000 g
Made in	RO	RO	RO	RO
Guarantee	3 years	3 years	3 years	3 years
Packing	1	1	1	1
Case quantity	3	3	3	3
EAN	3342540822429	3342540822436	3342540822443	3342540822450

Reference(s)	C071BA04	C071BA05
		
Color(s)	black	black
Size	1	2
Waist belt	70-93 cm	83-120 cm
Leg loops	47-62 cm	50-65 cm
Stature	165-185 cm	175-200 cm
Weight	2045 g	2125 g
Made in	RO	RO
Guarantee	3 years	3 years
Packing	1	1
Case quantity	3	3
EAN	3342540822467	3342540822474

---

**Accessory(ies)** CARITool  
TOOLBAG

---

**Related product(s)** ABSORBICA-Y European version  
GRILLON HOOK European version  
I'D@ S