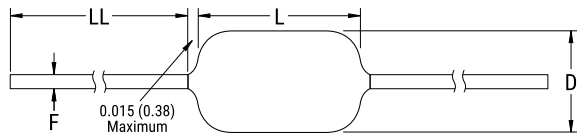


AxiMax 400 Comm C0G, Ceramic, 6800 pF, 5%, 50 VDC, C0G, AxiMax, Commercial Standard

**Dimensions**

D	3.81mm MAX
L	6.1mm MAX
LL	25.4mm MIN
F	0.51mm +0.025/-0.076mm

Packaging Specifications

Packaging:	Bulk, Bag
Packaging Quantity:	200

General Information

Supplier:	KEMET
Series:	AxiMax 400 Comm C0G
Description:	AxiMax, Commercial Standard
RoHS:	Yes
Termination:	Tin
Failure Rate:	N/A
Halogen Free:	Yes

Specifications

Capacitance:	6800 pF
Capacitance Tolerance:	5%
Voltage DC:	50 VDC
Dielectric Withstanding Voltage:	125 VDC
Temperature Range:	-55/+125C
Temperature Coefficient:	C0G
Dissipation Factor:	0.1% 25C
Aging Rate:	0% Loss/Decade Hour
Insulation Resistance:	100 GOhms