


Rittal – The System.

Faster – better – everywhere.

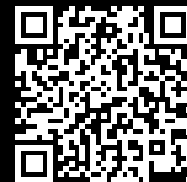

AX 6321.050

Compact enclosure AX

State: 2/12/2022 (Source: rittal.com/in-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AX 6321.050 - Compact enclosure AX Operating housing AX for desktop TFT up to 24"

The operating housing for desktop TFT up to 24" based on AX, sheet steel, with an integrated VESA 75/100 bracket. Effective and appealing protection for standard desktop TFTs up to 24" in the formats 16:9/16:10. High protection category IP 65.

Features

Model No.	AX 6321.050
Product description	For the installation of commercially available desktop TFTs with a screen diagonal of up to 24" in the formats 16:9/16:10.
Material	Enclosure: Sheet steel Door: Sheet steel, all-round foamed-in PU seal Handle strips: Aluminium Cover caps: Plastic Viewing window: Single-pane safety glass TFT holder: Sheet steel
Surface finish	Enclosure and door: Dipcoat primed, powder-coated on the outside, textured paint Handle strip: Natural anodised
Colour	Enclosure and door: RAL 7035 Handle strip: Natural anodised Cover caps: similar to RAL 7024
Supply includes	Enclosure with door, cut-out and reinforcement for support arm connection Ø 130 mm Viewing window Holder for desktop TFT with VESA 75/100 locator Side handle strips and cover caps Rear door with r/h hinge Cam lock with 3 mm double-bit insert Integral interior installation bracket with system punchings
Dimensions	Width: 650 mm Height: 450 mm Depth: 155 mm

Features

IP protection category to IEC 60529	IP 65
Standard	NEMA 1, 12
Type rating to UL 50E	Type 1, 12
Number of locks	2
IK Code	IK08
Note	<p>The support arm connection and door hinge may be swapped over by rotating the enclosure</p> <p>Optional: Support arm connection Ø 130 mm, preformed off-centre in the reinforcement plate, easily drilled out</p> <p>Lock systems for servicing access from the rear: Lock insert may be exchanged for mini comfort handle AX, 27 mm lock inserts, type A</p>
Basic material	Sheet steel
Lock	<p>Lock version: Cam</p> <p>Number locks: 2</p> <p>Lock insert: 3 mm double-bit</p>
Packs of	1 pc(s).
Weight/pack	18 kg
Copper weight (kg per piece)	0
Customs tariff number	94032080
EAN	4028177923249
ETIM 7.0	EC002504
ECLASS 8.0	27180505

Approvals

Approvals	<p>GOST</p> <p>UL + C-UL (listed)</p>
Explanations	Declaration of conformity