



Brand of NTN corporation


Technical data

BBET8UU

Super ball bushings



VISUAL (S)

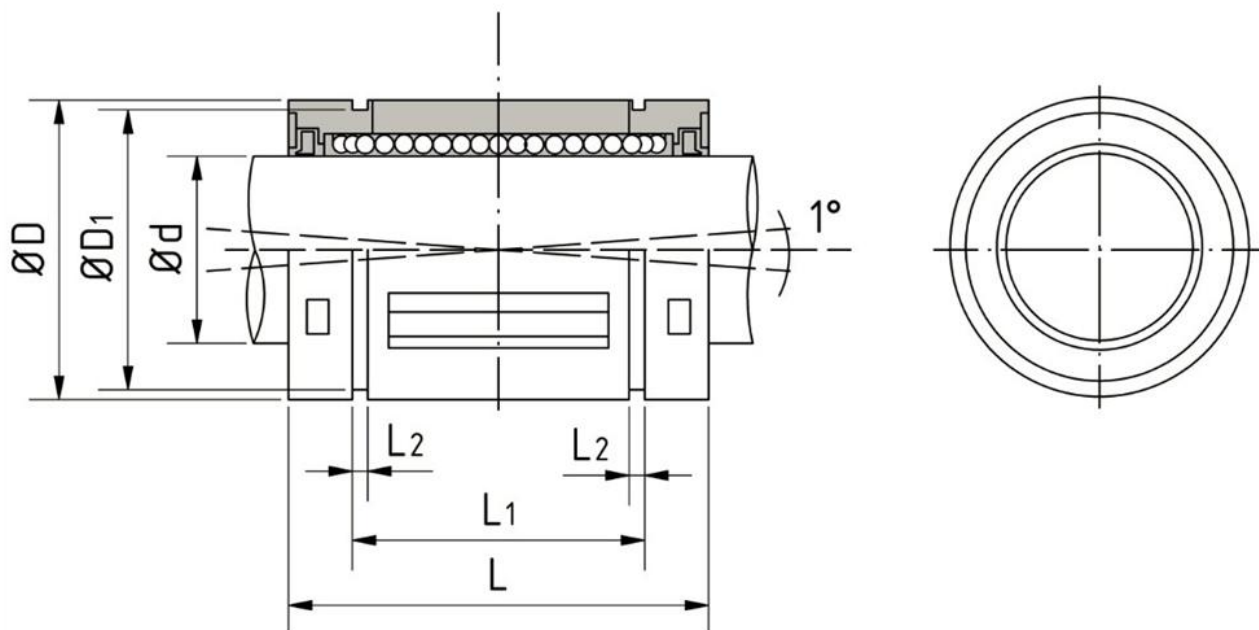

PRODUCT DEFINITION

Brand	SNR
Design type	BBET
Ball bushings category	Super ball bushings, closed
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
Re-lubricable	Oui/Yes



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Internal diameter	8 mm
d - Internal diameter tolerance	0,008/0
D - External diameter	16 mm
L - Length	25 mm
L - Length tolerance	0,2/-0,2
L1	16,5 mm
L1 tolerance	0/-0,2
D1 - Diameter	15,2 mm
L2	1,1 mm
Number of ball rows	4
Mass	0,007 kg

PRODUCT PERFORMANCE

Cmin	0,423 kN
Cmax	0,598 kN
C0min	0,534 kN
C0max	0,755 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY

Reference	BBET8UU
Image	BBET_1.JPG, BBET_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes



ESHOPDONOTDISPLAY

Tracepart

Oui/Yes

