


# Scriber

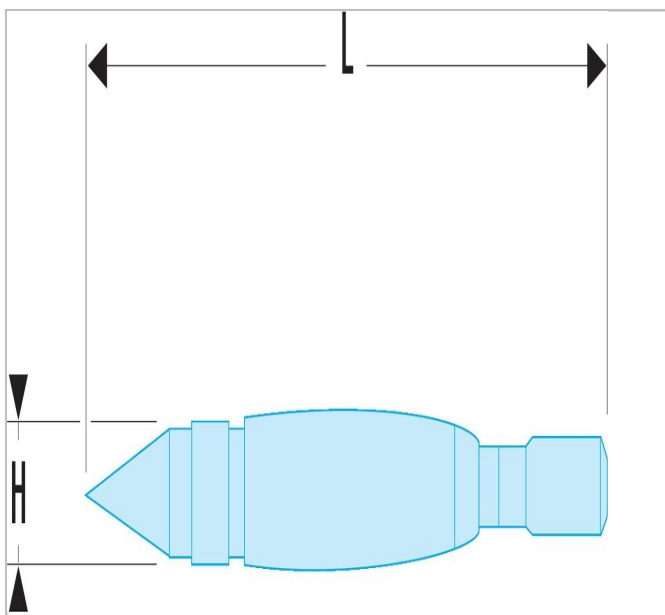

## Description:

- Pen shaped engraver makes the tool easy to handle.
- Tungsten point allows fast engraving on the hardest of materials: steel, stone, glass, ceramics at 600 impacts per second.
- Ring shaped regulator allows the operator to set the speed to suit his applications.
- Less than 80 dB(A) of sound increases operator comfort.
- Robust aluminium casted housing for high durability.
- Blows per minute 600 cpm.
- Working pressure 6,2 bar.
- Average air consumption 30 l/min.
- Average air consumption 1,1 l/min.
- Air inlet 1/4".
- Minimum hose diameter 10 mm - 3/8".
- Vibration 3,80 m/s<sup>2</sup>/a.
- Vibration 0,88 m/s<sup>2</sup>/K.
- Sound pressure 69,60 dB(A).
- Sound power 80,60 dB(A).
- Delivered with: - Supply hose 1.5 m. - A standard tip.
- Available as accessories: - Standard tip: V.820A1. - Fine tip: V.820A2.

	Height H [mm]	Length L [mm]	Weight [Kg]
V.820F	17.0	160.0	0.22