

IP20 FLEXIBLE LED TAPE +FLEX 80 HIGH CRI



4W/M



up to
599LM/M



IP20



Recycleable
Cardboard



>95Ra



2700K, 3000K
4000K, 6000K



100mm
Cut Points

FEATURES

- High CRI >95Ra
- Available in four different colour temperatures
- Industrial grade adhesive backing tape
- Working temperature -20°C - +45°C
- Humidity 40% - 70% RH
- 3 years warranty

SPECIFICATIONS

Stock Code	1013-243	1187-928	1188-418	1772-992
Part Code	B7-2-80-20-95	C0-2-80-20-95	D0-2-80-20-95	F0-2-80-20-95
Voltage	24VDC	24VDC	24VDC	24VDC
Power Consumption	4W/M	4W/M	4W/M	4W/M
Lumen Output	567LM/M	585LM/M	599LM/M	599LM/M
Efficacy	142LM/W	146LM/W	150LM/W	150LM/W
Tone (CCT)	2700K ●	3000K ●	4000K ●	6000K ●
LED/metre	80	80	80	80
LED Pitch	12.5mm	12.5mm	12.5mm	12.5mm
Cut Points	100mm	100mm	100mm	100mm
CRI	>95Ra	>95Ra	>95Ra	>95Ra
IP Rating	20	20	20	20
Dimensions	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm




2700K



3000K



4000K

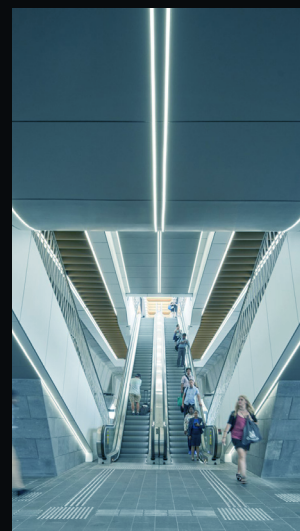

6000K

IP20 FLEXIBLE LED TAPE +FLEX 80 HIGH CRI



COMPATIBILITY



CONTROL METHODS

- Bluetooth (Apps, Voice Control) - BLE-15A
- Remote Control - SCD107W

SUGGESTED DRIVERS

Up to 1 M	Up to 5 M	Up to 10 M
Power supplied from ONE end	Power supplied from ONE end	Power supplied from the MIDDLE or BOTH ends
Non Dimmable	Non Dimmable	Non Dimmable
PCV2420	PCV2420	PCV2450
Mains Dimmable	Mains Dimmable	Mains Dimmable
UVC2425TD	UVC2425TD	UVC2450TD
DALI Dimmable	DALI Dimmable	DALI Dimmable
DA-30-24	DA-30-24	DA-50-24

*Other options available. Contact us for more information.

MECHANICAL DIAGRAM

