


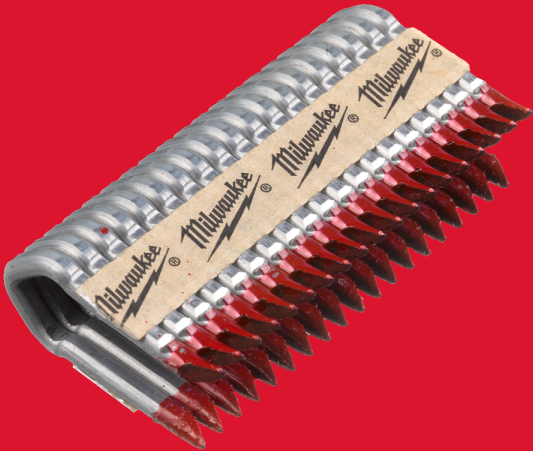

Fencing staples 40mm HDG-P960

STAPLES - FENCING

- Fencing staples for the Milwaukee M18 FFUS.
- For all types of wire fencing attached to wood ie. livestock fencing, square/chain/barbed wire and high tensile wire.
- Hot dipped galvanised coating for superior long term corrosion resistance.
- 4mm thick steel wire for best lifetime in outdoor applications.
- Sharp divergent point tips – the staple point tip twists as it is driven into the wood giving better holding power.
- Red adhesive coating for increased drivability while maximizing holding power.
- Paper tape collation for speed and convenience.



Fits MILWAUKEE®	Fencing staples for M18FFUS
Article Number	4932480358
Dimensions (Outer)(H x W x D / mm)	ø4
Material	Hot Dipped Galvanised
Nailers and Staplers (Configurator)	Milwaukee - M18 FFUS
Pack quantity	960
Service class	3
Total length (mm)	40
Width (mm)	20