
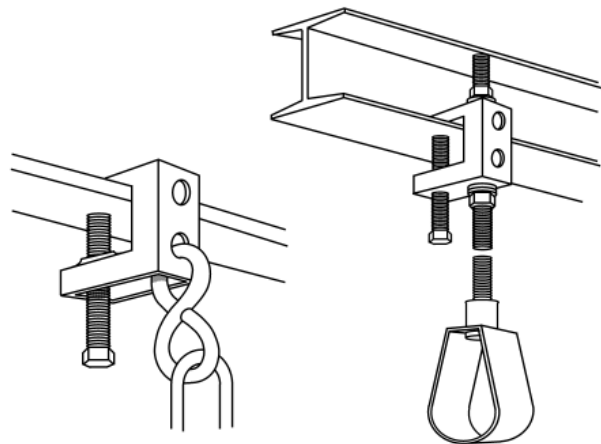


Datasheet

Girder Threaded Rod Clamp, maximum load 45kg, 16mm

RS Stock number [291-082](#)

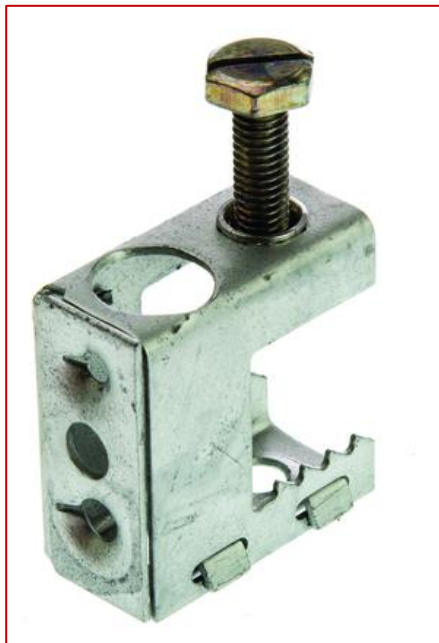


Description

Zinc silver coloured sacrificial coating (Z600+), enhanced by an application of waterproof topcoat giving a corrosion resistance of more than 600 hours, for use in indoor and outdoor humid and mildly corrosive environments. Coating is completely chromium free.

Specification

- | | |
|--------------------|-----------------|
| • Flange Thickness | Maximum of 16mm |
| • Hole Diameter | 10.7mm |
| • Material | Steel |
| • Maximum Load | 45kg |

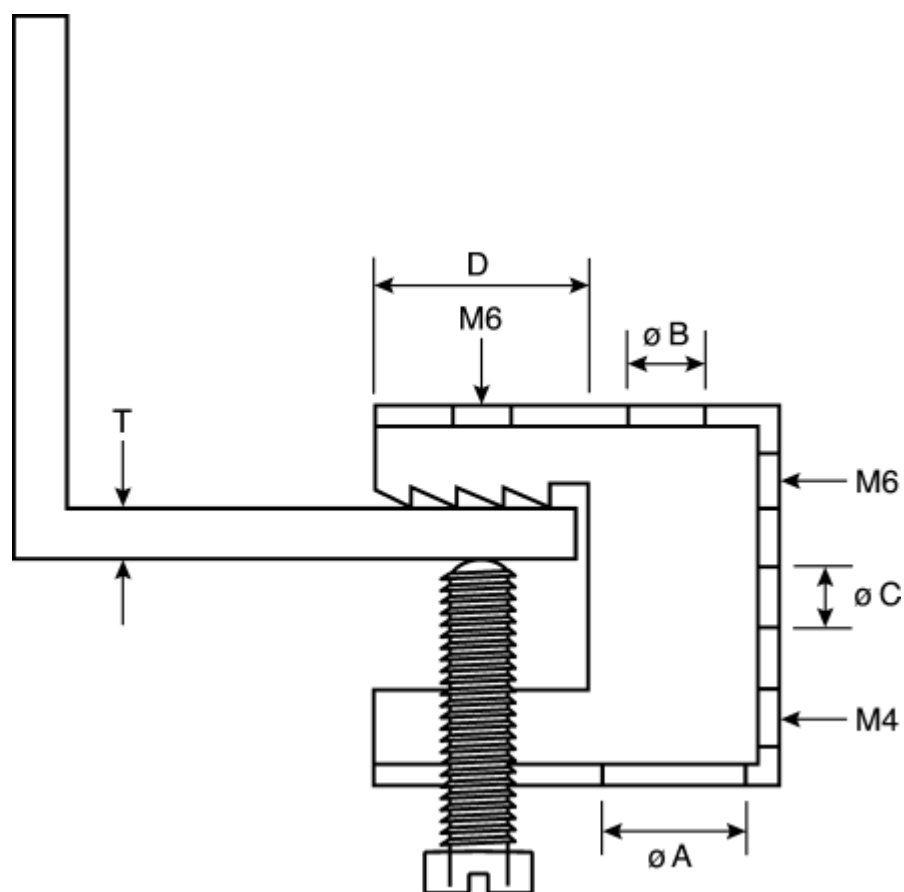

Measurements

- T: Max 16 mm
- $\varnothing A$: 10.7 mm
- $\varnothing B$: 6.5 mm
- $\varnothing C$: 10.7 mm
- D: 19.5 mm
- Load: 45kg