


400 series lugged cable entry boxes

Product overview

ABS boxes with mounting lugs and moulded cable entries. Supplied with flush-fitting lid.

- Moulded in ABS UL94-HB
- Press-fit flush lid (screw mounted lid 400-019)
- Lugs provide added security once mounted by restricting access
- 1x or 2x moulded cable entries (see table)
- Label recess in base (400-019 only)
- Highly resistant to most chemicals
- High-rigidity and impact strength
- Compliant with water absorption to DIN53495
- Maximum protection against shock, chemicals, moisture and temperature

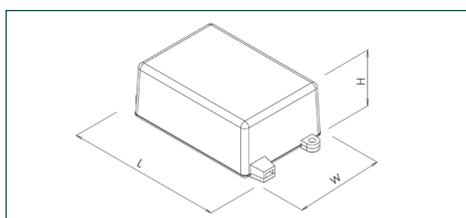

SPECIFICATION		
Materials	ABS	
Operating temperature	Resistant to continuous operating temperatures up to 70°C	
Standard colours	Black	
Standard unit includes	400-019	Lid and base
	400-011 to 400-017	2x fixing screws Lid and base



BLACK	CABLE INLETS	LENGTH	WIDTH	HEIGHT
400-011	3	65mm	38mm	22mm
400-013	3	65mm	38mm	27mm
400-015	3	72mm	44mm	22mm
400-017	3	72mm	44mm	27mm
400-019	2	82mm	57mm	33mm

KEY FEATURES

Moulded in ABS, UL94-HB | Highly resistant | High-impact strength

