
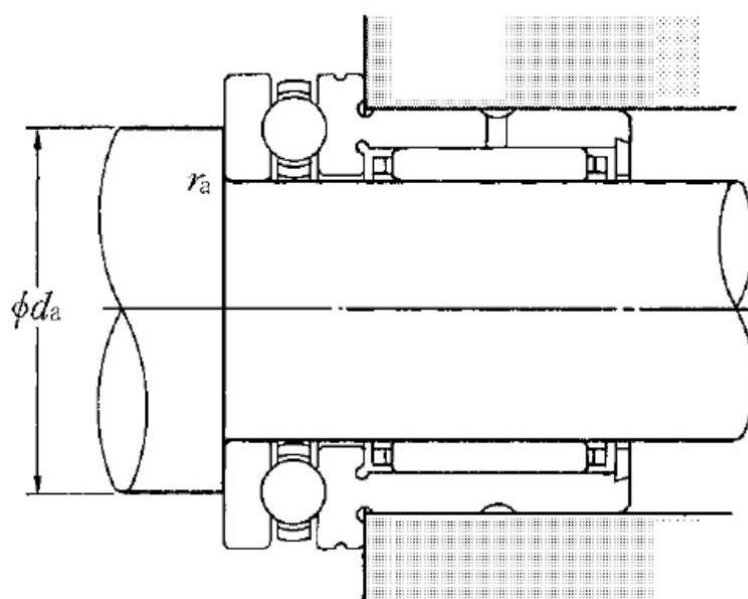


VISUAL (S)

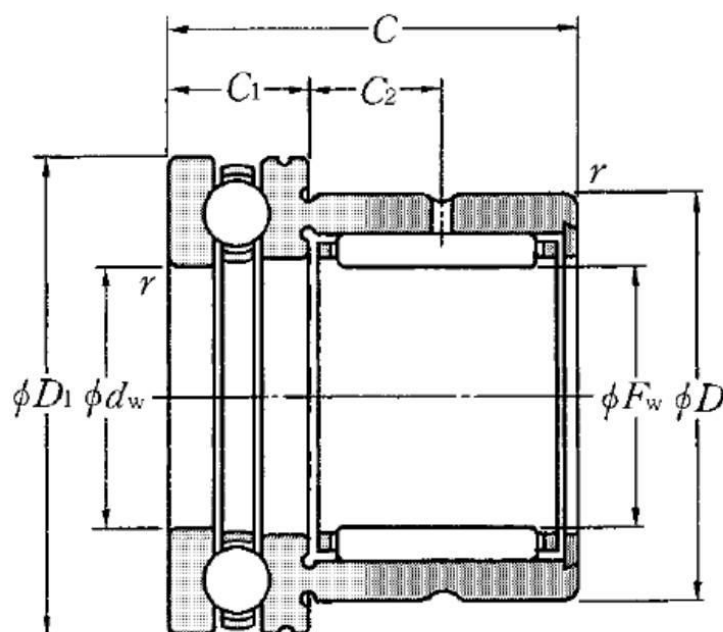

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	15 mm
dw - Shaft washer bore diameter	15 mm
D - External diameter	24 mm
D1 - Outer diameter of washer	28 mm
C - Width of bearing, drawn cup or outer ring	23 mm
C1 - Thrust bearing height	9 mm
C2 - Hole location	6,5 mm
rs - Min fillet radius	0,3 mm
Lubrication hole on outer ring	Oui/Yes
k - Hole diameter	2,5 mm
Precision class	P0
Mass	0,044 kg

PRODUCT PERFORMANCE

Cr - Dynamic load rating	8250000 mN
Ca - Dynamic axial load rating	10500000 mN
C0r - Static load rating	10200000 mN
C0a - Static axial load rating	16800000 mN
N lim - Grease lubrication limit speed	37200 °/s
N lim - Oil lubrication limit speed	52800 °/s
Tmin - Min operating temperature	253,15 °K
Tmax - Max operating temperature	393,15 °K



ABUTMENT	
da min - Min shoulder diameter IR	23 mm
ras max - Max shaft & housing fillet radius	0,3 mm

