

# 87 01 250

## KNIPEX Cobra® Hightech Water Pump Pliers



- Push the button for adjustment on the workpiece
- Fine adjustment for optimum adaptation to different sizes of workpieces and a comfortable handle width
- Self-locking on pipes and nuts: no slipping on the workpiece and low handforce required
- Gripping surfaces with special hardened teeth, teeth hardness approx. 61 HRC: high wear resistance and stable gripping
- Box-joint design for high stability due to double guide
- Reliable catching of the hinge bolt: no unintentional shifting
- Guard prevents operators' fingers being pinched
- Chrome vanadium electric steel, forged, multi stage oil-hardened

KNIPEX Cobra® - the Hightech Water Pump Pliers. No more time-consuming presetting of the required opening size. Just position the upper jaw to the workpiece, push button and move close the lower jaw, ingeniously simple.


<b>Article No.</b>	87 01 250
<b>EAN</b>	4003773034087
<b>Pliers</b>	grey atramentized
<b>Head</b>	polished
<b>Handles</b>	with non-slip plastic coating
<b>Adjustment positions</b>	25
<b>Nominal size</b>	250 mm
<b>Capacity for pipes, inches (diameter) Ø Inch</b>	2
<b>Capacities for pipes (diameter) Ø mm</b>	50
<b>Capacities for nuts mm</b>	46
<b>Length mm</b>	250
<b>Net weight g</b>	335




Fine adjustment by pushing a button: fast and comfortable.




Fast and firm adjustment directly on the workpiece

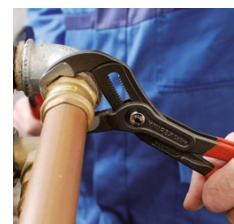

Teeth set against the direction of rotation have a self-locking effect and prevent slipping on the workpiece.

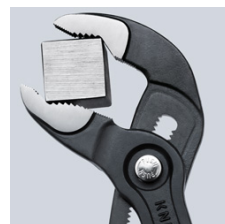

technical change and errors excepted

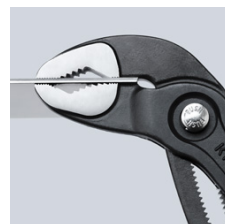



**Spare Parts**

<b>Article No.</b>	<b>EAN</b>	
87 09 01	4003773074724	Assortment of spare parts for adjustment for 86/87 250/300 ) without 87 2)