


## Datasheet

### Feed Through Terminal

RS Stock number 872-5628

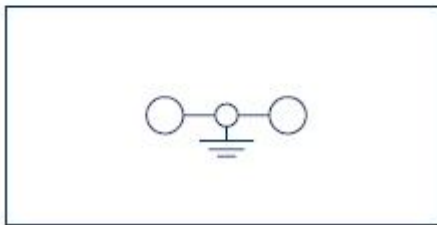

Protective earth terminal  
2 connections

### Features

- Foot can be snapped on TS 32 and TS 35 DIN rails
- Housing made from polyamide 6.6 UL 94-V2

### Specifications:

Rated wire cross-section, mm<sup>2</sup> | AWG: 2.5 | 22-12

Rated impulse voltage, kV | Contamination degree: 12 | 3

Plug gauge acc. to EN 60 947-1 | Flamm. class acc. to UL 94: A3 | V2

### Connection data

Single wire (solid) / Stranded mm<sup>2</sup>: 0.2-4 | -

Stranded/stranded (w/ferrules acc. to DIN 46 228/1) mm<sup>2</sup>: 0.2-4 | 0.2-2.5

Contact wire range, mm<sup>2</sup>: 0.2-4

Stripping length, mm: 10

Torque, Nm | Screw: 0.4-0.8 | Slotted M 2.5