
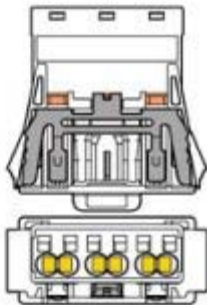


Item no.: 770-713/007-000
 Product description: PLUG SNAP IN TYPE 3 POLE 100% PROTECTED AGAINST MISMATING WITH DIRECT CONTACT OF THE GROUND CONDUCTOR

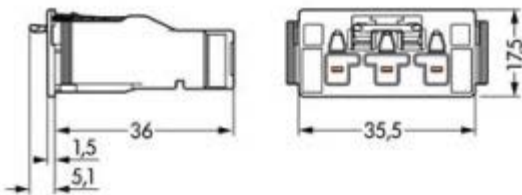

Packing unit 100 pieces

Product group	20 (WINSTA)
pole count	3
Cross section [mm ²]	0.5 - 4 mm ²
Cross section [AWG]	20 - 12 AWG
Connection method	CAGE CLAMP®S Connection
Number of strands	2
Measured voltage EN	250 V
Measured shock voltage	4 kV

Pollution degree	3
Current intensity EN	25 A
Weight	13.973 g
Color	black
No. of connection Points	6
No. of potentials	3
Height	17.5 mm
Height	0.689 in
Width	35.5 mm
Width	1.398 in
Depth	36 mm
Depth	1.417 in
Strip length from	9 mm
Strip length to	9 mm
Strip length	0.35 in

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected