


Features

- Pre-galvanised sheet steel
- Hot dipped galvanised inside and outside
- Wide selection of fittings

RS PRO Galvanised Steel Rigid Conduit Metal 20mm x 3.75m M20 x 1.5mm

RS Stock No.: 228-823

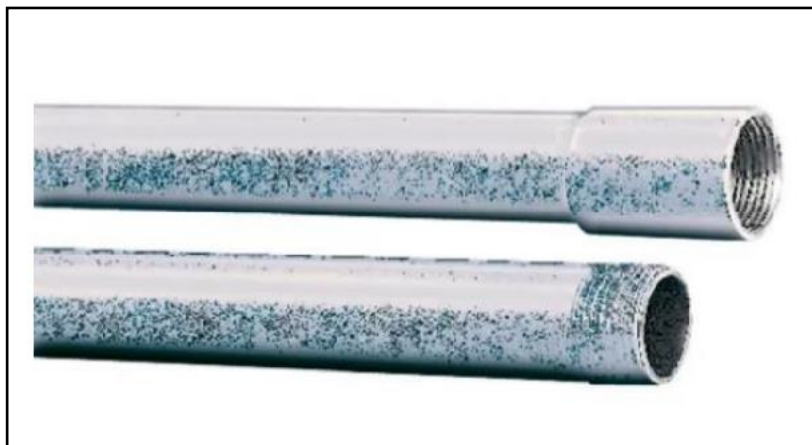

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Black enamelled or galvanised heavy gauge welded steel conduit. Threaded at both ends and supplied with one coupling per 3.75 m length with the choice of 20 mm or 25 mm sizes. A wide selection of fittings and accessories are available to assist in the most demanding or effortless installations.

For Conduit Cables see stock no. 381-012 typically

For Cable and Wire pulling lubricants see stock no. 196-3407 typically

General Specifications

Conduit Type	Rigid
Material	Galvanised Steel
Colour	Black
Coating Material	Uncoated

Mechanical Specifications

Nominal Diameter	20mm
Length	3.75mm
Thread Size	M20 x 1.5mm

Approvals

Standards Met	BS4568
---------------	--------