

OUAZ-SH-112L,900

 SUPERSEDED

OEG

TE Internal #: 6-1419130-5

TE Internal Description: OUAZ-SH-112L,900

[View on TE.com >](#)



Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2022 (224) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Customers Also Bought




TE Part #CSA264F48440020000
940 PLUG, SPEEDTEC




TE Part #ASA035F01400235000
623 PLUG

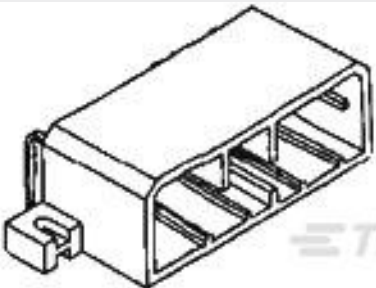

TE Part #173862-1
070 MULTILOCK CAP ASSY 18P

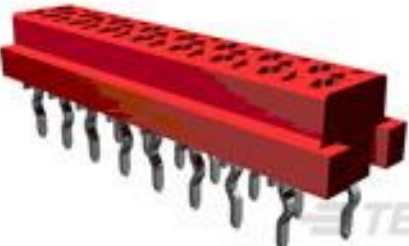

TE Part #8-215079-6
MICRO-MATCH FOB.16P

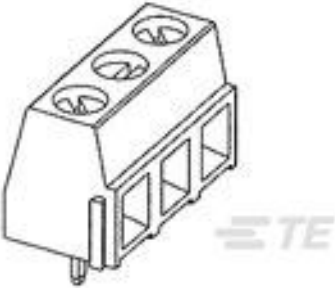

TE Part #282836-6
TERMI-BLOK PCB MOUNT 90 6P.



TE Part #1-1437012-0
609-003=HDW IDC JCKSOCKET ASSY



TE Part #3-1624113-5
3650 0805 27nH 5% 2K RL



TE Part #3-1625892-7
3W SM M/OX 5% 2K2



TE Part #1825058-7
ADE04S04=DIP SWTCH,EXT,SMT-GW



TE Part #2351460-1
MINSA SW HLV 0.30N 0.5A AC SC
UnPtch

Documents

Product Drawings

OUAZ-SH-112L,900

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_6-1419130-5_E4.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_6-1419130-5_E4.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_6-1419130-5_E4.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



OUAZ series Relay data sheet English

English

Agency Approvals

UL

English