**FAG****UKP209** **Plummer block housing unit**

Plummer block housing units UKP, cast iron housing, with long base, radial insert ball bearing with adapter sleeve, RSR seals

**Technical information****Your current product variant**

Material	GG	Grey cast iron
Housing clearance	J7	Normal swivel torque

**Main Dimensions & Performance Data**


d	40 mm	Bore diameter
L	190 mm	Length total
H <sub>2</sub>	106 mm	Height
≈m	2.29 kg	Weight

**Mounting dimensions**

J	146 mm	Distance fixing bore
N	17 mm	Width (slot)
N <sub>1</sub>	21 mm	Length (slot)

**Dimensions**

H	54 mm	Distance shaft axis
A	54 mm	Width (base)
H <sub>1</sub>	20 mm	Height (base)
B <sub>1</sub>	50 mm	Locking collar total width
Q	M6	Connection thread for lubrication

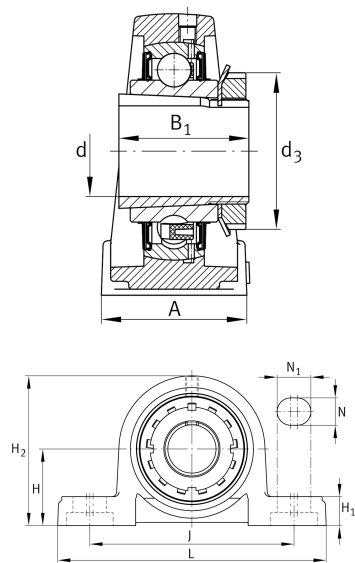



Additional information

P209	Housing
UK209	Bearing designation

Temperature range

T <sub>min</sub>	-20 °C	Operating temperature min.
T <sub>max</sub>	120 °C	Operating temperature max.