


Datasheet




 
 


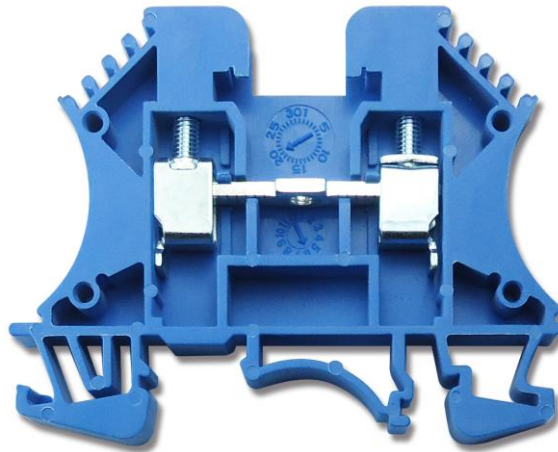

Stock No: 913-1210

Screw Clamp Terminal Blocks, 4sq.mm

35A, 600V, 22-8 AWG, 0.5-4 sq.mm, Blue



Specifications:

Specifications		4mm ²
Technical Data		Rated voltage / Rated current / Wire size
UL		600V / 35A / AWG 22-8
CSA		600V / 35A / AWG 22-8
IEC		800V / 32A / 0.5-4mm ²
Insulating impulse voltage withstand/pollution degree		8KV / 3
Torque (in -lbs)		7.7
Clamping Screw (M)		M3
Insulation stripping length (mm)		10~12 mm
Net weight per piece		9.1g
Material / Available Color (Standard Color: Beige)		<div style="display: flex; justify-content: space-around; align-items: center;"> <div style="text-align: center;"> ● Beige 878-7519 </div> <div style="text-align: center;"> ● Blue 913-1210 </div> </div>
Rail Dimensions		T / W / H (mm)
For TS35x7.5		6.1 x 60 x 47.3
For TS35x15		6.1 x 60 x 54.8
Accessories		Cat. No.
End Bracket		878-7553
		878-7556
End plate		878-7540
Cross		878-7581
		913-1302
Marking Tags		913-1282
		913-1318

Dimensions in mm:

