


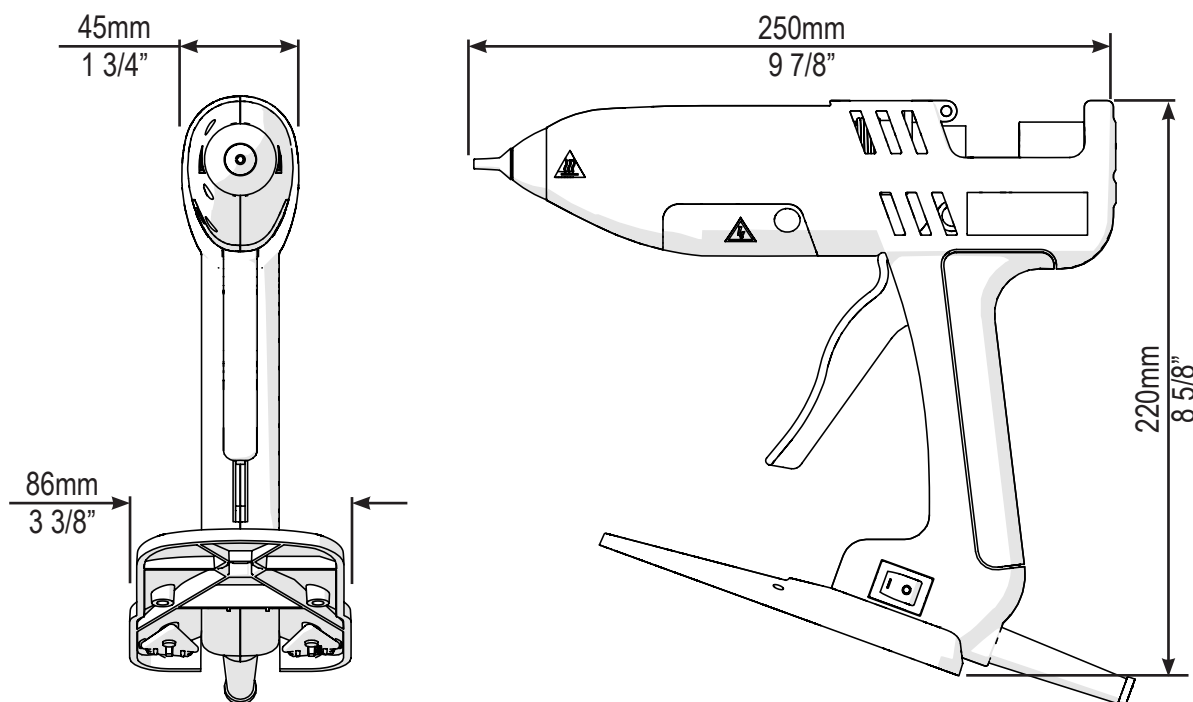

	Tec 810-12	Tec 810-15
Type	Trigger action glue gun	
Glue size	12mm (1/2") glue stick	15mm (5/8") glue stick
Melt rate	2.0kg (4.5lb) / hr	2.0kg (4.5lb) / hr
Voltage	120V & 230V	
Wattage	250W	300W
AC Hz	AC 50-60Hz	
Heater	Cartridge	
Temperate control	Interchangeable thermostat	
Temperature (hotmelt)	160° (320°F), 180° (356°F), 195° (380°F), 215° (419°F)	
Temperature (lowmelt)	130° (265°F)	
Weight	770g (27oz)	
Power cable	3m (10') permanently attached flexible cable with plug	
Plug variants	UK, Euro, USA, CH, ZA, AU, 110V	
Packaging	Cardboard box - 325 x 250 x 80mm (1kg / 2.2lb) 10 per outer carton - 340 x 450 x 540mm (11kg / 24.25lb)	
Approvals	UKCA, CE	
Warranty	12 months from date of purchase	

Power Adhesives Limited

1 Lords Way, Basildon, Essex, SS13 1TN, England

Telephone: +44 (0)1268 885800 Fax: +44 (0)1268 885810

E-mail: sales@poweradhesives.com Website: www.poweradhesives.com