

## **Brush module for Euro faceplates**



### **Aperture brush modules for Euro faceplates XBR(wh/bk) XBR(wh/bk)G2**

TUK's brush modules easily convert standard Euro faceplates into popular brush faceplates, providing a tidy exit for cables exiting a wall or trunking. They simply snap-in to single gang (86x86mm) or twin gang (86x146mm) faceplates and are available in white or black.

#### **Features:**

- Suitable for installers or faceplate manufacturers
- Snap easily into place
- Suitable for 50x50mm or 50x100mm openings in Euro single gang (86x86mm) or twin gang (86x146mm) faceplates
- Available in individual poly bags or in bulk packs of 50.

#### **Specifications:**

- Net weight (including primary packaging): XBRwh/bk - 10g, XBRwh/bkG2 - 18g
- Dimensions (including primary packaging): XBRwh/bk 55x55x13mm, XBRwh/bkG2 55x105x13mm
- Colour: Black or White

Materials: ABS plastic frame with Nylon brush.

**Packaging:** Individual poly bags then in 20's or in bulk packs of 50

**Commodity code:** 85177090

**EAN:**

**Singly packed:**

**XBRwh** 5055386510747

**XBRbk** 5055386510754

**XBRwhG2** 5055386510761

**XBRbkG2** 5055386510778

**Packed in 50's:**

**XBRwh#50** 5055386510785

**XBRbk#50** 5055386510792

**XBRwhG2#50** 5055386510815

**XBRbkG2#50** 5055386510808

**Country of Origin** China



**Aperture brush modules for Euro faceplates XBR(wh/bk) XBR(wh/bk)G2 back view**





**Illustrative Image**

ROHS Compliant

Code: XBr\*


\*= bk or wh

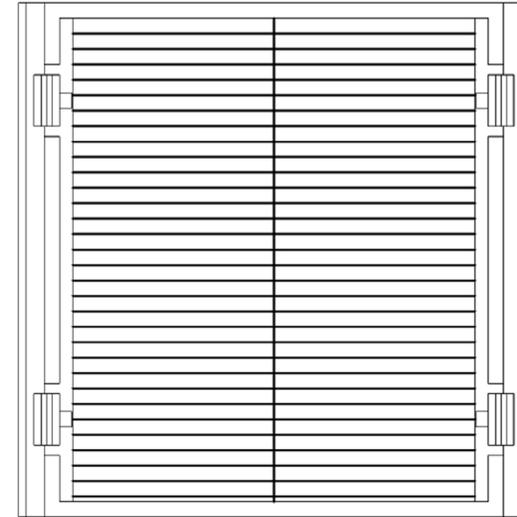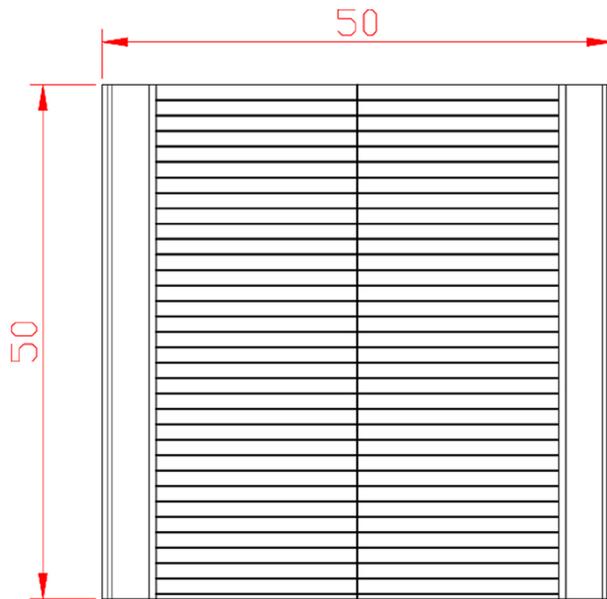

Material ABS



**Tolerance**

0.00-20.00	±0.10
20.00-50.00	±0.15
50.00-100.00	±0.20
100.00-	±0.25
Angle	±30°

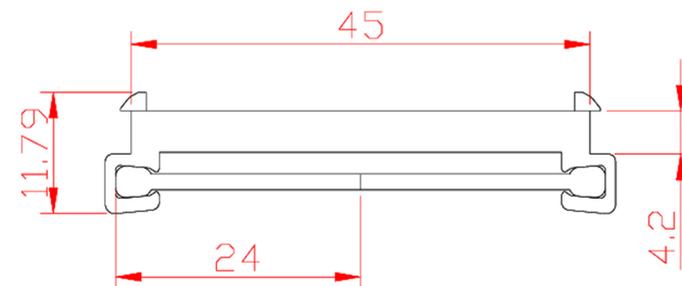

ROHS Compliant

Code: XBr\*G2  
 \*= bk or wh

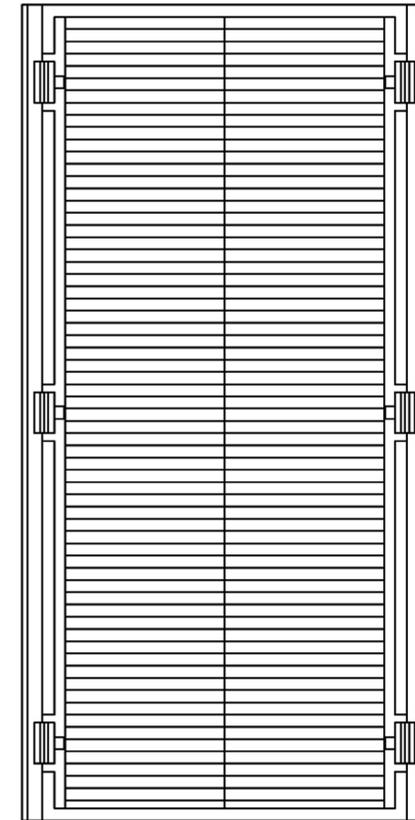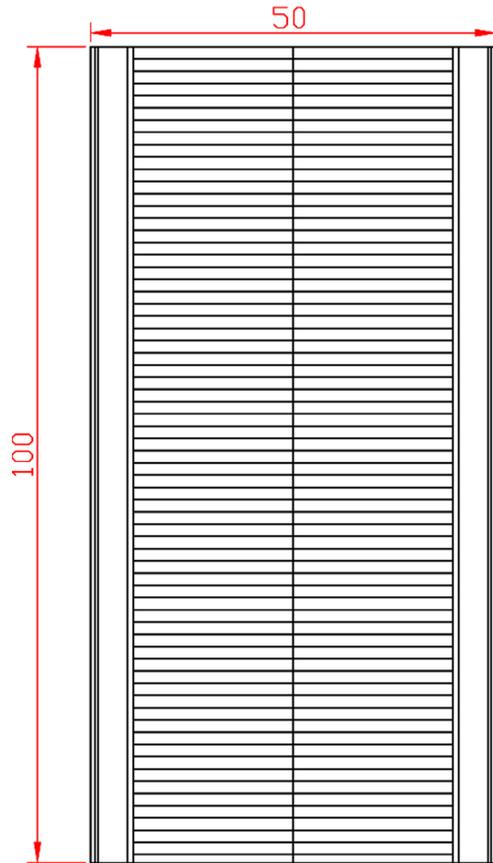

Material ABS

**Tolerance**

0.00-20.00	±0.10
20.00-50.00	±0.15
50.00-100.00	±0.20
100.00-	±0.25
Angle	±30°

