


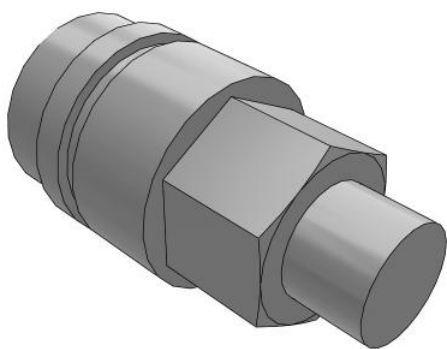

KK*S-*M, S-Couplers, Male Thread KK6S-03MS




Datasheet

- Male thread.
- Body size: M5, 1/8, 1/4, 1/2.
- Applicable Port Size: M5, R1/8, R1/4, R3/8, R1/2, R3/4.

Standard specifications

Body Size	6 (1/2)
Piping Port Size	R 3/8
Sealant	S (With Sealant)
-	Air, Water
Maximum operating pressure	1.0 MPa
Minimum operating pressure	0 kPa
Proof pressure	1.5 MPa
Effective Area	82 mm ²
Sealing principle	Electroless nickel plated (copper-free application), With male thread sealant
Weight	0.085 Kg

Dimensions

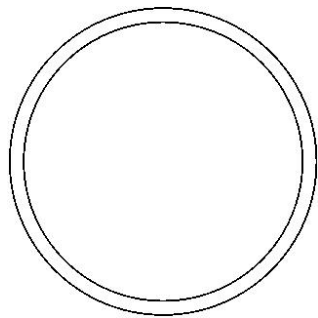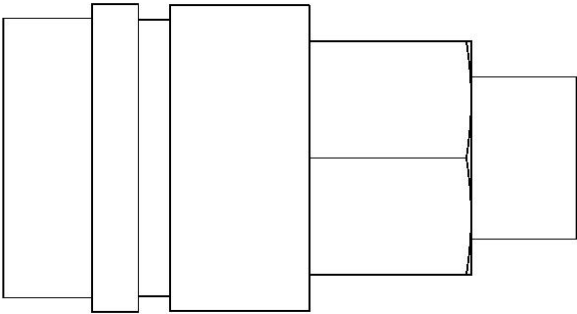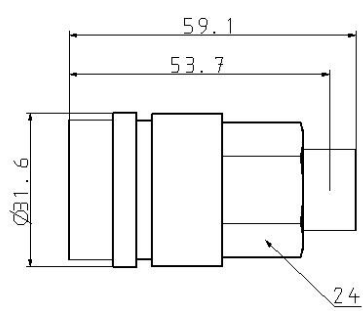

Additional information

Catalogue

[KK-C_EU.pdf](#)