

Cast resin, Polyurethane resin (PUR) green, 1950ml

Art.-No. 435-12122 | Resin-33-SF-N-PUR-GN | 



- In a practical, transparent two-chamber pouch
- Colour changes from blue to green whilst mixing
- Safe-Filling system (SF)
- Excellent flow properties, low volume shrinkage
- Cold curing and very hydrophobic, can be submerged directly after casting
- High hydrolytic stability and good curing at low temperatures
- UV, ageing and weather resistant
- Outstanding impact strength and resistance to moisture and atmospheric corrosion
- Excellent adhesion to polymeric cables and wires made of PVC, XLPE, PE, EPR
- SVHC-free, contains no hazardous substances, the cured

•



More products in this product group:

[Two-component polyurethane cast resin >](#)


Application	The RELICON PUR 33 cast resin has been created for the electrical insulation and mechanical protection of cable connections in low-voltage electrical networks. Also suitable as mechanical and moisture protection on medium-voltage cable connections. Application: For indoor and outdoor use.
Colour	Green (GN)
Density	1.37 g/cm ³ , 20 °C (DIN EN ISO 2811-2)
Material	Polyurethane resin (PUR)
PART DESCRIPTION	Resin-33-SF-N-PUR-GN
Pack Content	1950 ml
Package Content packed in	bag
Pot Life	43 min. 5°C, 15 min. 23°C, 8 min. 40°C
Product Family	RELICON PUR 33
Product Group	Two-component polyurethane cast resin
Type	Resin-33-SF-N
Viscosity	4500 mPa*s, 5 °C (EN ISO 2555), 3000 mPa*s, 23 °C (EN ISO 2555)

Product Dimensions

Shore Hardness D	65±5
------------------	------

Specifications

Dielectric Strength	38 kV/mm
ELV compliant (Article 4 - 2)	YES
Halogen-free	Yes
Hazardous Goods	No
Impact Strength	26 kJ/m ²
Operating Temperature	-25 °C to +120 °C
ROHS compliant	Yes
Shelf Life	48 months
Specifications	HF ✓ RoHS ✓
Specifications	Cenelec HD 631.1 S2

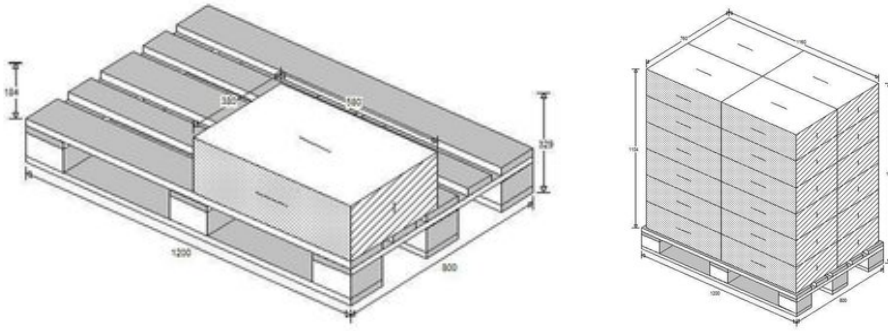

GTIN-13 / EAN	4031026628325
Packaging 1 - Type	carton
Packaging 3 - Height (m)	0.184 m
Packaging 3 - Length (m)	0.58 m
Packaging 3 - Qty	5
Packaging 3 - Type	box
Packaging 3 - Volume (m ³)	0.0406 m ³
Packaging 3 - Weight (kg)	17.06 kg
Packaging 3 - Width (m)	0.38 m
Packaging 4 - Height (m)	1.255 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	120
Packaging 4 - Type	pallet
Packaging 4 - Volume (m ³)	1.205 m ³
Packaging 4 - Weight (kg)	430.44 kg
Packaging 4 - Width (m)	0.8 m
Spray content	2672 g
Storage Temperature	+4 °C to +40 °C

More Information