


TV3220

## VMS Basic

The video management software VMS Basic is an optional upgrade for all video surveillance systems delivered with VMS Express. The distinguishing features of VMS Basic are the ability to manage 16 channels – being 7 more than VMS Express – and an extended set of configuration options and functions that are important for professional use. Further examples are the manual configuration of storage processes, numerous alarm functions and defining individual movement patterns.

Despite the extended functionalities, the ease of use and a concise layout of the user interface have been emphasized. Upgrading VMS Express to VMS Basic is done quickly and easily: Simply insert the USB dongle, install the new version over the old one, and there you go. All settings that you made in VMS Express are taken over.

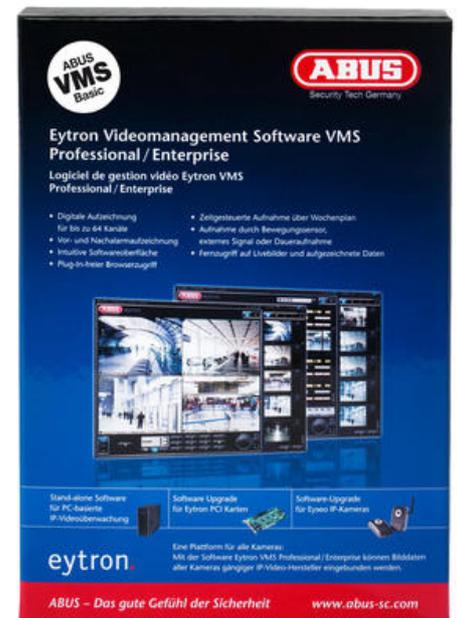

### Product highlights:

- Integration of up to 16 cameras
- Remote access via Internet browser and PDA
- Support of every ABUS Security-Center IP cameras und PCI-carts
- Programmable recording a time schedule and event control

TV3220

## VMS Basic

### Technical Data

|  |   |                                  |   |
|--|---|----------------------------------|---|
| Total number of channels (IP + analog) | 16  | Alarm reaction                   | Programmable                              |
| Operating mode                         | Triplex (simultaneous recording, playback and network access)   | Types of notifications           | E-mail, FTP, on-screen / on-screen remote |
| Remote access via browser              | Max. 1 users  | Remote access and control        | LAN/WAN                                   |
| Remote access to Eytron                | Max. 1 users  | PDA access                       | Yes                                       |
| HDVR and NVR systems                   |   | Support for dynamic IP addresses | Yes                                       |
| Hybrid-capable                         | Yes   | Webserver function               | Yes                                       |
| IP camera protocols                    | ABUS Security-Center  | Controller for speed domes       | Yes                                       |
| Resolution                             | Megapixel, 4CIF/D1, 2CIF, CIF   | Cash point connection            | No  |
| Bitrate per channel                    | 1.0 / 1.5 / 2.0 / 3.0 / 4.0Mbit   | Password protection              | Yes                                       |
| Multi-monitor function                 | No  | USB dongle                       | Yes                                       |
| Backup medium                          | DVD, USB, LAN   | UVV-Kassen certified             | No  |
| Pre-/post-alarm ring buffer            | Up to 20 minutes  | Languages                        | German, English, French, Danish, Dutch    |
| Recording control                      | <input type="checkbox"/> Programmable, in the event of video failure, fault, alarm, motion, masking, distortion, scheduled, permanent |                                  |   |
| Video failure detection                | Yes, with alarm list entry and programmable event reaction  |                                  |   |