




Product information

Name: Speedi-Roll

Designation: LLEHS 35 Speedi-Roll

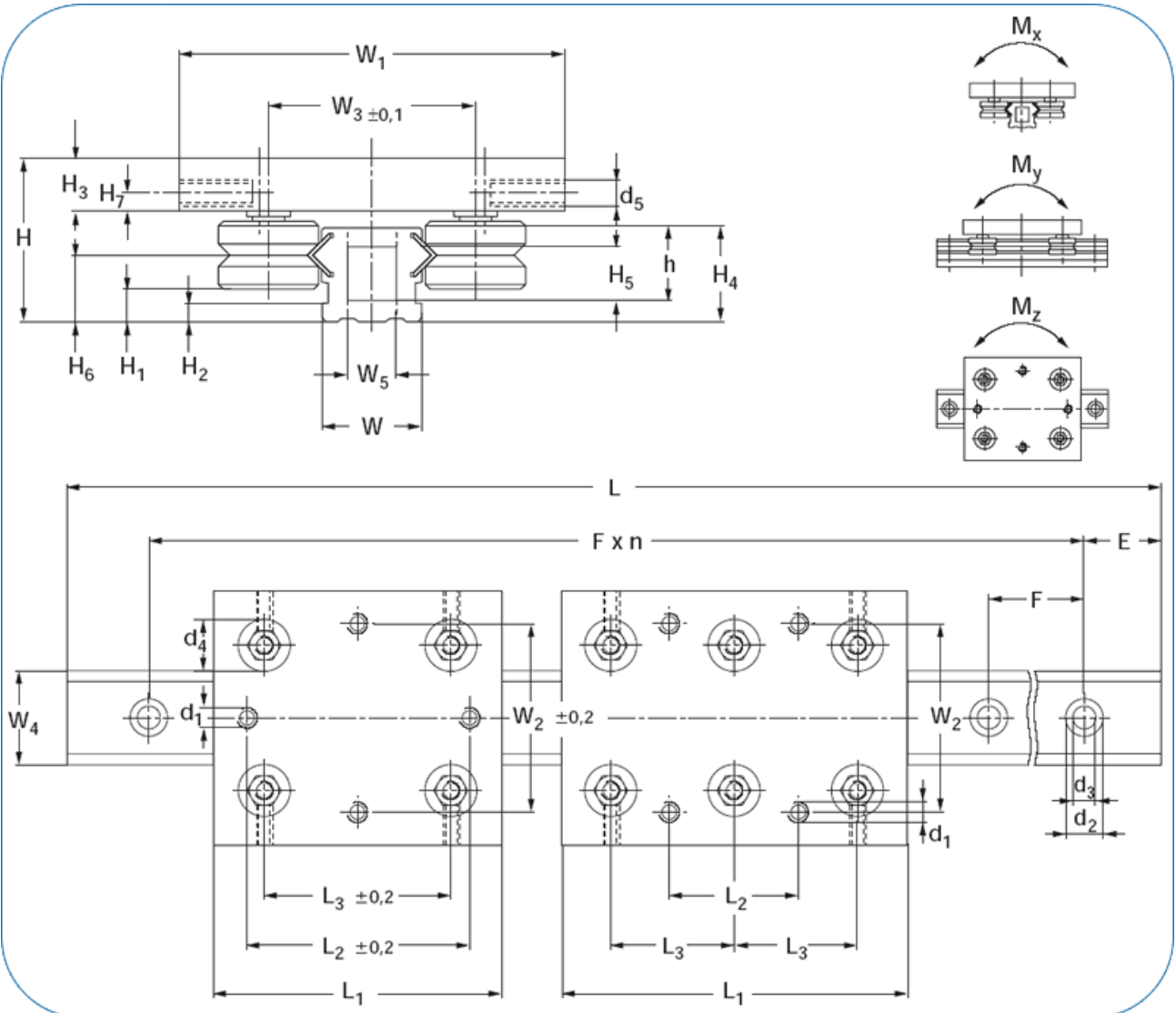

Product specifications

Range		Guiding system
H	[mm]	54,3
H1	[mm]	12,35
W1	[mm]	120
Carriage type		Standard

Please choose your country with the top menu

Product specifications (Next page)

L1	[mm]	100
W2	[mm]	90
L2	[mm]	70
W3	[mm]	61,3
L3	[mm]	65
H3	[mm]	19,4
d1		M 10
d4	[mm]	21
rail width	W	[mm] 36
W4	[mm]	42,9
H2	[mm]	7
H4	[mm]	29
width	W5	[mm] 20
H5	[mm]	15
H6	[mm]	22,75
d2	[mm]	20
d3	[mm]	11
h	[mm]	22
F	[mm]	250
E	[mm]	125
L	[mm]	4 000
Foy	[N]	2 500
Foz	[N]	2 500
Mox	[Nm]	70
Moy	[Nm]	76
Moz	[Nm]	35
weight of rail	[kg]	2
weight of carriage	[kg]	0,9