

HC-EVO-B16-BWSC-PLRBK - Housing



1407647

<https://www.phoenixcontact.com/gb/products/1407647>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Panel mounting base B16, with single locking latch, material: PA 6.6-FR, protective cover material: PC, height: 30.5 mm, cable gland: none, protective cover: yes, Standard, with flat gasket

Your advantages

- Lower costs than metal version
- Low weight
- Lower risk of condensation

Commercial data

Item number	1407647
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF7APL
Product key	BF7APL
Catalog page	Page 618 (C-2-2019)
GTIN	4046356777100
Weight per piece (including packing)	126.5 g
Weight per piece (excluding packing)	126.5 g
Customs tariff number	85389099
Country of origin	PL

HC-EVO-B16-BWSC-PLRBK - Housing



1407647

<https://www.phoenixcontact.com/gb/products/1407647>

Technical data

Notes

General	For contact inserts HC-B16, BB32, D40, DD72, HS6, HV6, M, K, HV06-I-PR, HV 6-E...C
---------	--

 
Product properties

Product type	Housing with locking latch
Housing type	Panel mounting base
Product family	HC-EVO-B
Application	Standard
Type	B16
Protective cover	yes
Pg screw connection	none

Data management status

Article revision	05
------------------	----

Dimensions

Dimensional drawing	
Width	53 mm
Height	30.5 mm
Length	114 mm
Drill hole distance, horizontal	103 mm
Drill hole distance, vertical	32 mm
Hole diameter	4.5 mm

Installation dimensions

Width of the assembly cutout	35 mm
Length of the assembly cutout	86 mm

Material specifications

Flammability rating according to UL 94	V0 (Housing)
	V0 (Interlock)
	V0 (Protective cover)
Seal material	NBR
	NBR
Housing material	PA 6.6-FR
Material, protective cover	PC
Locking latch material	PA

Mechanical properties

HC-EVO-B16-BWSC-PLRBK - Housing



1407647

<https://www.phoenixcontact.com/gb/products/1407647>

Mechanical data

Locking type	Latch
--------------	-------

Connection data

Tightening torque	0.8 Nm ... 1.2 Nm (For M4 mounting screws on the panel-mount base)
-------------------	--

Mounting

Assembly note	Not for D series terminal adapters
	Not for HC-B 24-ADP-B..... adapter plates

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66 (when plugged in or with locked protective cover)
Enclosure rating (NEMA)	12 (UL 50e)
Impact strength	IK08
Ambient temperature (operation)	-40 °C ... 125 °C

HC-EVO-B16-BWSC-PLRBK - Housing


1407647

<https://www.phoenixcontact.com/gb/products/1407647>




Drawings

Dimensional drawing

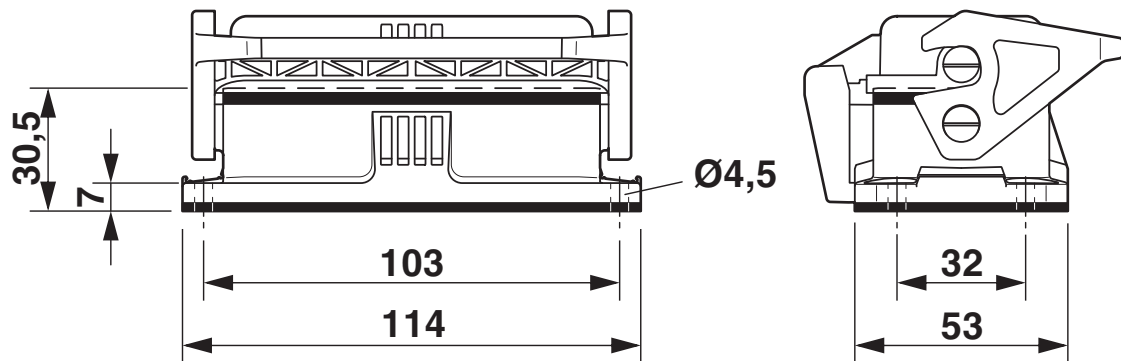

Dimensional drawing

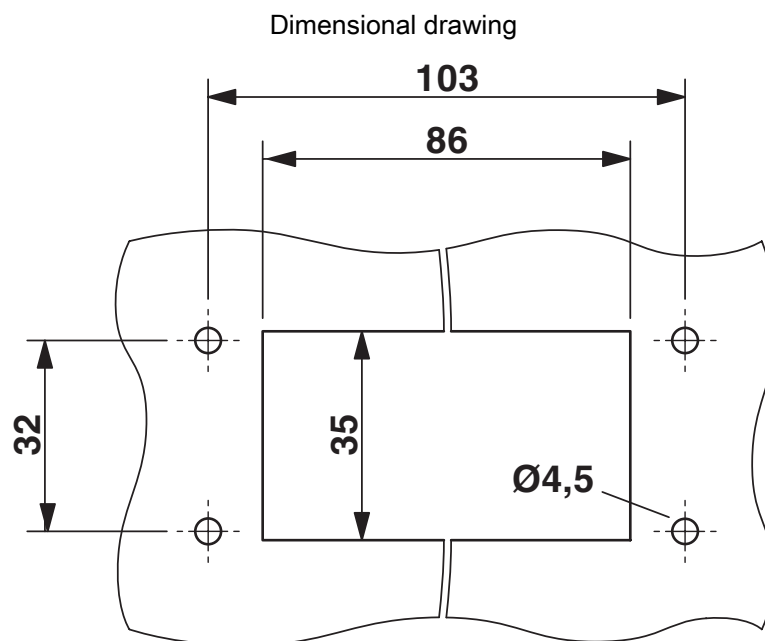

Mounting cutout

HC-EVO-B16-BWSC-PLRBK - Housing



1407647

<https://www.phoenixcontact.com/gb/products/1407647>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/gb/products/1407647>

DNV
Approval ID: TAE000037S

EAC
Approval ID: RU C-DE.AI30.B.01102

EAC
Approval ID: RU C-DE.BL08.B.00511

HC-EVO-B16-BWSC-PLRBK - Housing



1407647

<https://www.phoenixcontact.com/gb/products/1407647>

Classifications

ECLASS

ECLASS-11.0	27440202
ECLASS-12.0	27440202
ECLASS-13.0	27440202

ETIM

ETIM 9.0	EC000437
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%