


PX0410/04S/4045 Datasheet

Product Name // Flex Cable Connector PX0410 Series 4
Contact Socket 4.0mm-4.5mm Cable

 [View Product Page](#)

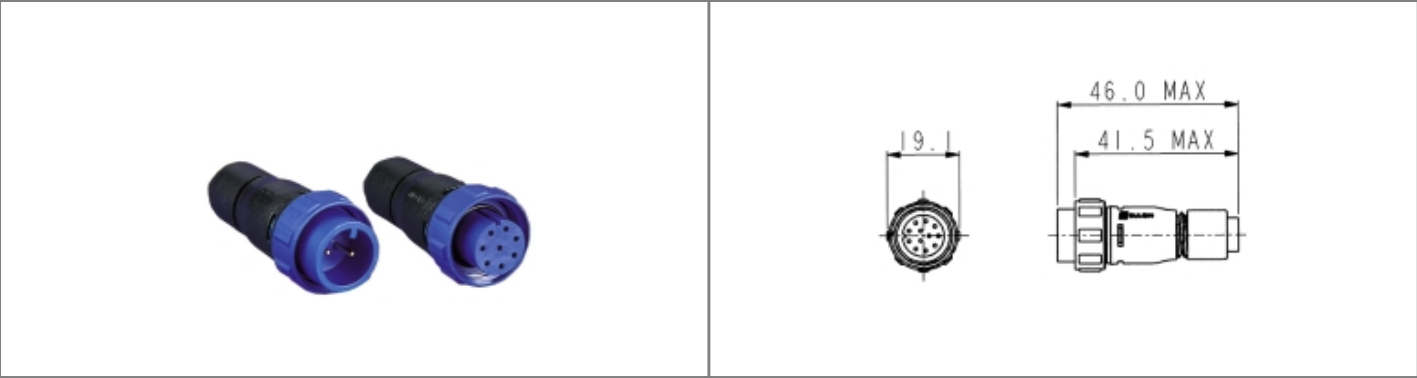

// **Product Description:**

- Flex Cable Connector
 - Water and dustproof to IP68 when mated with compatible connector
 - Pin or Socket
 - 2, 3, 4, 6, 8, 10 or 12 Contact
 - Crimp or Solder Contacts available (supplied separately; use 8A for 2/3 Contact, 5A for 4/6/8 Contact, 1A for 10/12 Contact)
- Contact insertion and crimp tools available (supplied separately)
 - Choice of cable acceptance 3mm-7mm depending on part code; supplied with Cable Gland and Collet colour coded by size
 - PX0481 Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mate with Inline or Panel Mount Connectors PX0401, PX0411, PX0412, PX0413

// **General Information:**

Product Display Title:	Flex Cable Connector
Product Family:	Circular Power Connectors
Product Series:	400 Series Buccaneer
Approvals:	UL
Body Material:	Polyamide (PA)
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	5A
Diameter Over Coupling Ring Mm:	19.1mm
Flamability Rating:	UL94V-0
Function:	Flex Cable Connector
Ip Rating:	IP68
Max Cable Entry Size:	4.5mm
Min Cable Entry Size:	4.0mm
Max Contact Accomodation Awg:	26AWG
Min Contact Accomodation Awg:	22AWG
Max Contact Accomodation Mm2:	0.34mm2
Min Contact Accomodation Mm2:	0.14mm2
Max Operating Temperature:	+80°C
Min Operating Temperature:	-40°C
Number Of Contacts:	4 Contacts
Voltage Max:	125V

// **Product PDF Links**

-  [400 Series power connectors...](#)
-  [400 Series power connectors wiring...](#)

// **Product 3D CAD Model Links**

-  [PX0410/04S/40453D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)