




Heat Shrinkable Tubing 2:1 flexible and transparent

- TF24

Protects wire and cable markers subject to abuse, while permitting inspectability of each item covered. Protects electronic components while permitting their identification and inspection.

Features and Benefits

- Transparent, flexible polyolefin tubing
- Protects identification marking perfect
- Halogen free
- Good mechanical and chemical resistance
- VG-approval and additional industrial approvals

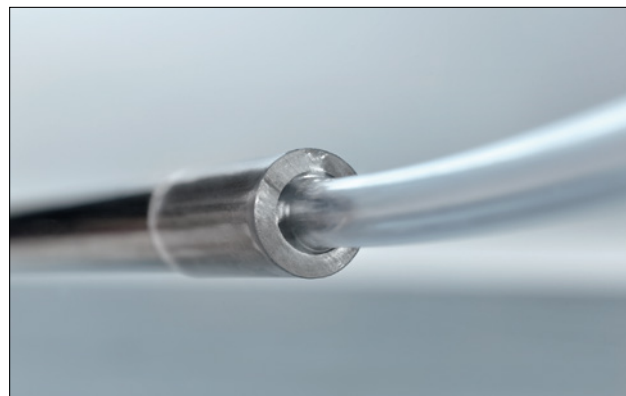

TF24 transparent tubing with 2:1 shrink ratio.

Cut lengths available on request. Please contact us!



One Step to the Web!

MATERIAL	Polyolefin, cross-linked (PO-X)
Shrink Ratio	2:1
Operating Temperature	-55 °C to +135 °C
Minimum Shrink Temperature	+110 °C
Longitudinal change after shrinkage	+/-5% max.
Dielectric Strength	≥ 30 kV/mm min. according to ASTM D2171
Flammability	not flame retarded
Specifications	DEF STAN 59-97 Type 2B, SAE - AMS - DTL-23053/5 Class 2, VG 95343



Heat Shrinkable Tubing 2:1



TYPE	Supplied Ø D min.	Recov. Ø d max.	Wall (WT)	Reel Length	Colour	Designation as per VG-Norm	Article-No.
TF24-1.2/0.6	1.2	0.6	0.41	100 m	Transparent (CL)	VG95343T05B001M	309-40123
TF24-1.6/0.8	1.6	0.8	0.43	100 m	Transparent (CL)	VG95343T05B002M	309-40163
TF24-2.4/1.2	2.4	1.2	1.51	100 m	Transparent (CL)	VG95343T05B003M	309-40243
TF24-3.2/1.6	3.2	1.6	0.51	100 m	Transparent (CL)	VG95343T05B004M	309-40323
TF24-4.8/2.4	4.8	2.4	0.51	60 m	Transparent (CL)	VG95343T05B005M	309-50483
TF24-6.4/3.2	6.4	3.2	0.64	60 m	Transparent (CL)	VG95343T05B006M	309-50643
TF24-9.5/4.8	9.5	4.8	0.64	50 m	Transparent (CL)	VG95343T05B007M	309-40953
TF24-12.7/6.4	12.7	6.4	0.64	50 m	Transparent (CL)	VG95343T05B008M	309-41273
TF24-19.1/9.5	19.1	9.5	0.76	50 m	Transparent (CL)	VG95343T05B009M	309-31903
TF24-25.4/12.7	25.4	12.7	0.89	50 m	Transparent (CL)	VG95343T05B010M	309-32543
TF24-38.1/19.1	38.1	19.1	1.02	60 m	Transparent (CL)	VG95343T05B011M	309-33813
TF24-50.8/25.4	50.8	25.4	1.14	60 m	Transparent (CL)	VG95343T05B012M	309-35083
TF24-76.2/38.1	76.2	38.1	1.27	30 m	Transparent (CL)	VG95343T05B013M	309-37603
TF24-101.6/50.8	101.6	50.8	1.40	15 m	Transparent (CL)	VG95343T05B014M	309-31023

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.



Please note! Not all products listed on this page may have this approval.
For product specific approvals please refer to the Appendix.