

**BOSCH**


Invented for life

Product data sheet

Power tools for trade & industry

Cordless Caulk Gun

PRO GCG 18V-600

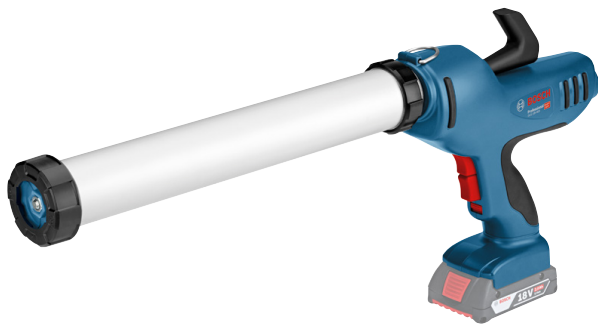

Bosch's 1st Cordless Caulk Gun: 100% compatible with all Bosch Professional 18 V batteries

The most important data

Battery voltage	18.0 V
Push Force	3.5 kN
Capacity Cartridges	310 ml, 400 ml

Order number 0 601 9C4 001

Technical data

Technical data

Battery voltage	18.0 V
Push Force	3.5 kN
Capacity Cartridges	310, 400
Capacity Sachets	400, 600
Feed rate	7 mm/sec
Weight excl. battery	2.2 kg
Packaging dimensions (width x length x height)	357 x 729 x 94 mm

Noise/vibration information

Total vibration values

Vibration emission value ah	1.5 m/s ²
Uncertainty K	2.5 m/s ²



Product data sheet

Power tools for trade & industry

Advantages:

- Easy control of material flow: Speed selection with 9 speed settings and variable speed trigger
- Fast working progress even with high viscosity adhesives: 3.5 kN push force combined with a maximum (no load) feed of 7 mm/sec
- No dripping or material overflow: Plunger rod auto-reverse function relieves pressure when trigger is released



You can find more information about the deviations in the following link: <https://www.bosch-professional.com/au/en/wac/>

