




Datasheet


RS PRO LOUVERED FILTER FAN KIT 230VAC 209×209×97mm and SLIDING GUARD

Stock number: 175-9793

EN

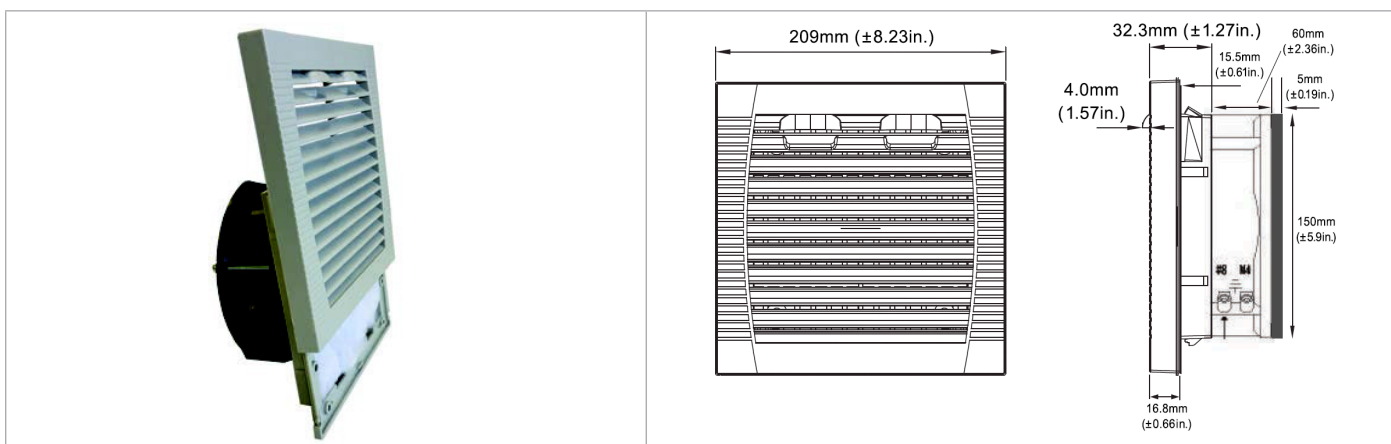

Frame	Diecast Aluminum	<u>Operating Temperature</u> Ball Bearing -40C ~ +70C
Impeller	PBT, UL94V-O plastic	<u>Life Expectancy</u> >60,000 hours (L10, 40C)
Connection	Terminals	<u>Environmental:</u> Class B Insulation Rated IP54 Guard Guard Frame: ABS Resin UL94V-O with UV protection Color: Gray (standard) or Black (special order) Filter Mesh: Nylon fiber Synthetic Resin
Motor	Capacitor drive, impedance protected	
Bearing System	Dual ball bearing	
Insulation Resistance	>100M ohm between lead-wire and frame (500VDC)	
Dielectric Strength	1 min at 1500 VAC, 50/60Hz	

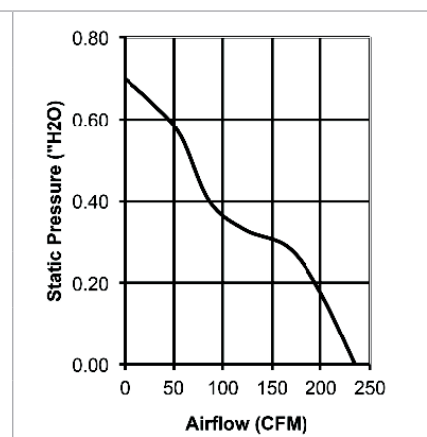

Model Number	175-9793
Volts	230
Voltage Range	160 ~ 260 VAC
Rated Power	35 W
Rated Speed (RPM)	3200
Airflow (CFM)	235
Noise Level (dB)	52
Max. Static Pressure	1.70\" H ₂ O