

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1110150101](#)
Status: **Active**
Overview: HSAutoLink™ Interconnect Systems
Description: HSAutoLink Cable Assembly, USCAR/USB TYPE A Receptacle-to-MINI-B Plug, 0.50m Length, Polarization B

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-68800-001-001 \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	111015
Assembly Configuration	Dual Ended Connectors
Comments	USCAR-30 Compliant
Connector to Connector	USB Type A-to-Mini-B
Overview	HSAutoLink™ Interconnect Systems
Product Name	HSAutoLink USCAR/USB
UPC	883906510077


Physical

Cable Length	0.50m
Circuits (Loaded)	N/A
Gender	Male-Female
Lock to Mating Part	Yes
Net Weight	39.180/g
Packaging Type	Bag
Single Ended	No
Wire/Cable Type	Round

Material Info

Reference - Drawing Numbers

Product Specification	PS-68800-001-001
Sales Drawing	SD-111015-006

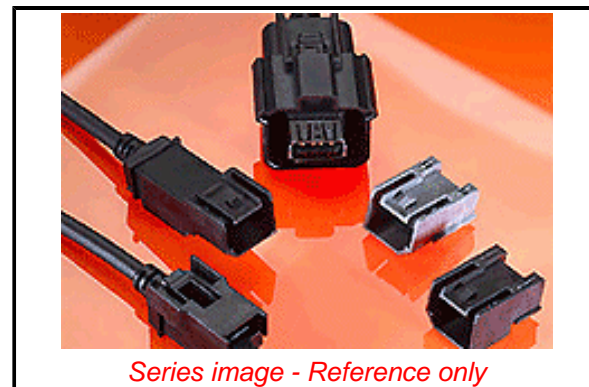

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/108/2014 (17 Dec
2014)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Reviewed

Search Parts in this Series

[111015](#) Series

Mates With

[49616](#) USCAR/USB Header