


Grey Soft Rubber Trolley Wheel 50mm, 35kg

Thermoplastic rubber-tyred wheel

PRODUCT

Article number

380 511

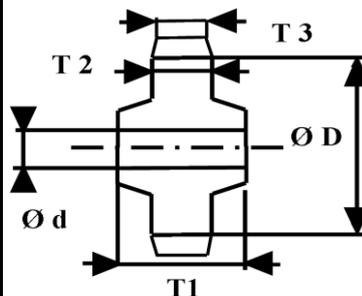

Product Details

Wheel Rim : made of grey impact-resistant polypropylene.

Tread : grey soft rubber, integrated type. Non-marking.

Hub : symmetrical with plain bore and steel threadguards.

Delivered with M6x30 bolt

Specifications

Wheel Diameter - ØD ± 1%	50 mm
Hub Type	Plain
Hub Length T1	20 mm ±1
Width of Tread T2	18 mm ±1
Width of Tread-on floor T3	18 mm ±1
Axle Hole Ø d	Ø 8 mm
Hardness of tread A ±3	A 80° Shore
Load capacity	35 Kg
Temperature	-10 / +50 °C
Bolt	Hexagonal Head M6X30
Weight	0,05 Kg

TECHNICAL DATA

Applications :

Quiet and non-marking materials handling.

Lightweight, low starting effort.

Suitable for all interiors floors (warehouses, offices, shops, kitchens,...).

Smooth and silent movement thanks to the shock-absorbing tread.