


Features

- UL approved Nylon 66, 94V-2
- Color: Red, Yellow, Blue, Green, Orange.
- Feature: Low Smoke and Halogen Free cable tie suitable for various industry, also household DIY and gardening.
- Application: One piece self-lock cable tie save the time and make effective for installation.
- Easy to thread.

RS PRO Cable Ties

RS Stock No.: 233708

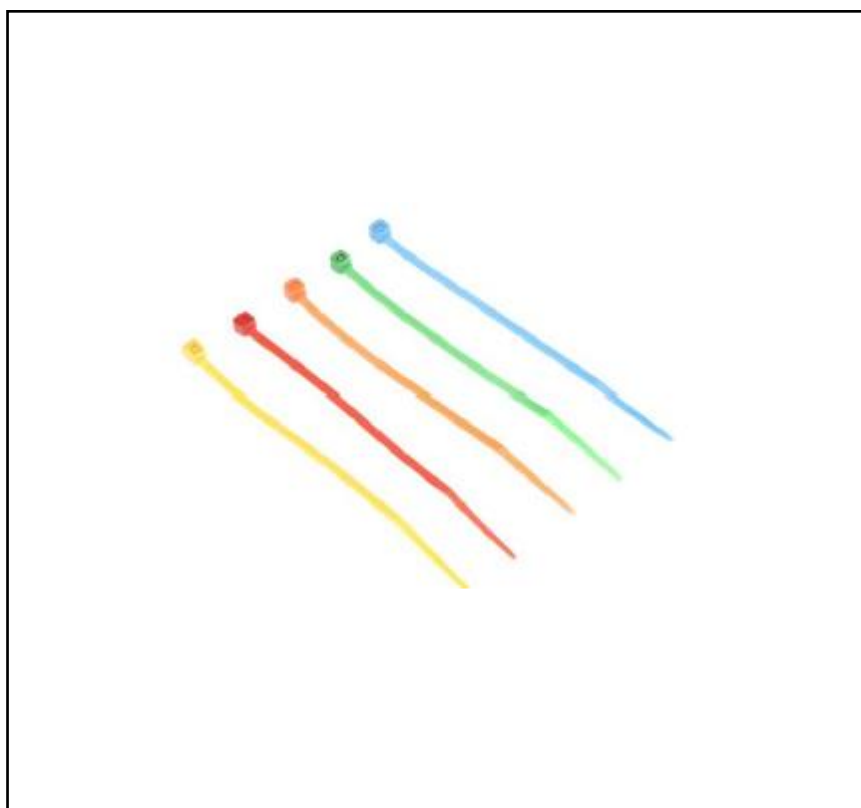

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

These cable ties are made from Nylon 66(also known as nylon 6.6) and ate a one-piece, self-locking fastener that functions like straps o keep cables tide. Each pack contains 250 non-releasable cable ties, comprising 100 each of red, yellow, blue, green and orange to enable color coding of cables or components. Ideal for cable and wire management.

General Specifications

Type	Non-Releasable
Colour	Red, Yellow, Blue, Green, Orange
Material	Nylon 66
UV Resistant	Weather Resistant
Minimum Operating Temperature	-40°C
Maximum Operating Temperature	85°C
Fire Behaviour	Self-Extinguishing

Mechanical Specifications

Length	203mm /8"
Width	4.6mm / 0.18"
Min. Loop Tensile Strength(lbs/kgf/N)	50lbs / 22kgf / 222N
Maximum Bundle Dia.	52mm

Approvals

Standards Met	UL, RoHS, SVHC, DNV.GL, Lloyd's, CE, VDE, ABS, HF
---------------	---

