

Features

- Double Shut Off
- Maximum Operating Pressure 1000 Bar
- Ball Lock
- Operating Temperature from -30 °C to +100 °C
- Steel
- Plastic Dust Plug Included
- Interchangeable:

CEJN 115
CEJN 115FF

RS PRO Hydraulic Quick Connect Couplings

RS Stock No.: 0727372



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

The RS PRO 85 Series hydraulic quick connect couplings are heavy-duty designed for demanding hydraulic applications. Here are the key features:

Here are the key features:


- **Screw-to-Connect Design**
Ensures secure, vibration-resistant connections, ideal for high-pressure and pulsating hydraulic circuits
- **High Pressure Capability**
- **Robust Construction**
- **Non-Spill Valve System**
Prevents fluid leakage during disconnection, reducing contamination and environmental hazards.
- **Safety Locking Mechanism**
Screw connection ensures positive locking, preventing accidental release under load
- **Dust Plug for Coupling**

Applications: **construction machinery, agricultural equipment, oil & gas, and industrial hydraulic systems** where high pressure and vibration resistance are critical.

Attention: The Coupler and plug should not be loaded before connection

Interchangeability:

- CEJN 115
- CEJN 115FF

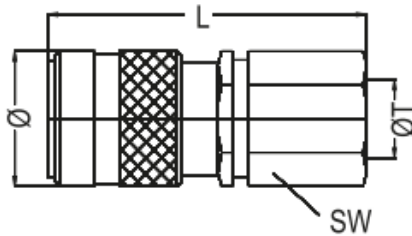

Female Threaded Shut-Off Coupler



T Connection	Ø D (mm)	L (mm)
G 1/4"	27	62.9

Specifications

Manufacturer Series	85
Compatible with	CEJN 115 CEJN 115FF
Maximum Operating Pressure	1000 Bar
Minimum Operating Temperature	-30 °C
Maximum Operating Temperature	+100 °C
Type	Quick Connect Coupling
Locking Style	Ball Lock
Double Shut Off	Double Shut Off
Thread Size	1/4 in
Thread Standard	G
Thread Gender	Female
Coupling Gender	Female
Thread	G 1/4 in Female
Material	Steel
Finish	Free-cutting steel
Seal Material	Nitrile Rubber
Sleeve Material	Steel
Valve Material	Steel
Spring Material	14310
Locking O Ring Material	AISI-316

