

Data sheet Product SL 4 025 72 G




PCB connectors>Male headers
 male header □ 0.635 mm, dimensions "A" + "B" changeable

Features

pitch:	2.54 x 2.54 mm
no. of contacts:	72
contact material:	CuSn-alloy
surface of contact:	gold-plated
surface contact / contact sleeve:	• Ni+≥0.2µm Au • Ni+4...6µm Sn
version:	insertion side dimension "C", "S" selective gold-plated
volume resistance:	≤5 mΩ
nominal current:	3 A
nominal voltage:	250 V AC
test voltage:	2000 V
insulating body material:	PA 4.6. GF
temperature range:	• -40°C... +163°C • (260°C/10 s)
class of inflammability:	UL 94 V-0
specific insulation resistance:	>10 ⁷ Ω·m
connection type:	THT (soldering)
reflow solderable:	yes

Technical Drawing

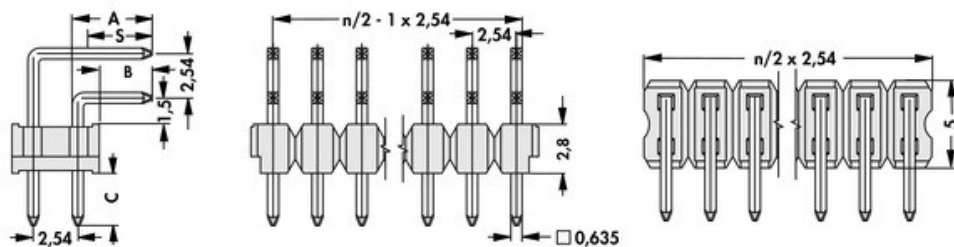

A:	4.5 mm
B:	3 mm
C:	5.8 mm
S:	5.0 mm

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de