




Switches > Push Button Switches

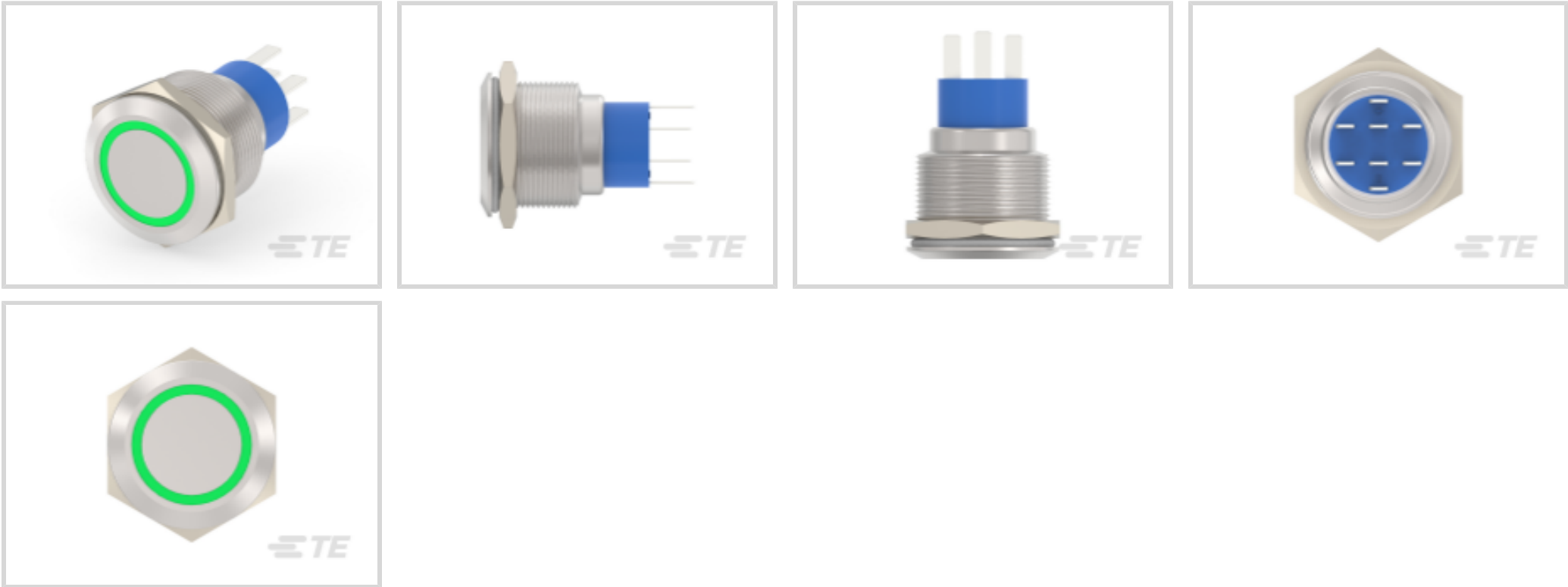

Push Button Switch Product Type: **Anti-Vandal Switch**
Configuration (Pole-Throw): **Double Pole - Single Throw**
Number of Actuators: **Single**
Actuator Profile: **Flush**
Bushing Style: **Threaded**

Features

Product Type Features

Switch Connection Type	Wire Lugs
Push Button Switch Product Type	Anti-Vandal Switch
Illuminated	With
Actuator Style	Round Actuator

Configuration Features

Configuration (Pole-Throw)	Double Pole - Single Throw
Number of Actuators	Single
Snap Action	Without
Support Bracket	Without
Switch Feedback Type	Auditory
Operating Function	Momentary

Electrical Characteristics

Contact Current Rating	3 A
Operating Voltage Range	250 VAC



Body Features

Case Material	PBT
Product Orientation	Vertical
Actuator Force	357 g[12.6 oz]
Actuator Profile	Flush
Bushing Style	Threaded

Contact Features

Switch Contact Plating Material	Silver
---------------------------------	--------

Housing Features

Process Sealed	Yes
----------------	-----

Dimensions

	22 in
--	-------

Industry Standards

IP Rating	IP67
-----------	------

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) SVHC > Threshold: Pb (4% in Component Part) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent




chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

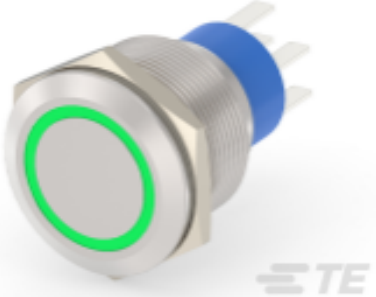


TE Part # 5-2213772-5
AV22 DPM 3A MOVE RING LED GREEN 24V

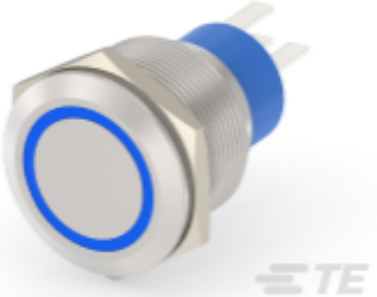


TE Part # 1-2213772-7
AV22 SPM 3A MOVE RING LED BLUE 12V

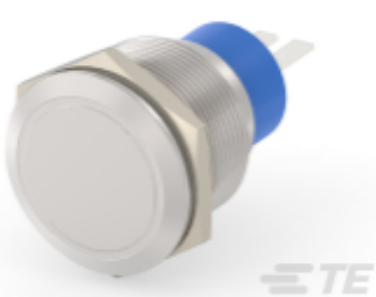

TE Part # 2213771-1
AV22 SPM 3A NO LED

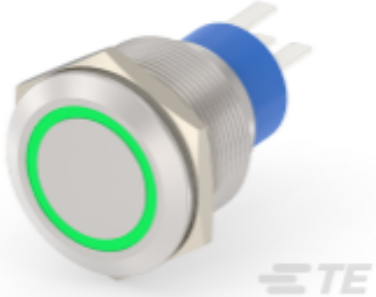


TE Part # 1-2213772-3
AV22 SPM 3A MOVE RING LED GREEN 12V

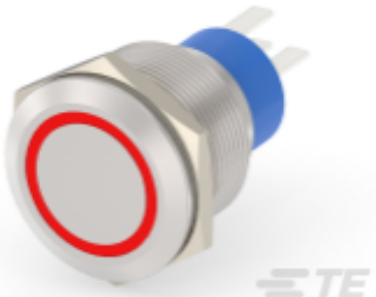

TE Part # 2213772-5
AV22 SPM 3A MOVE RING LED RED 12V

Also in the Series | Alcoswitch AV22

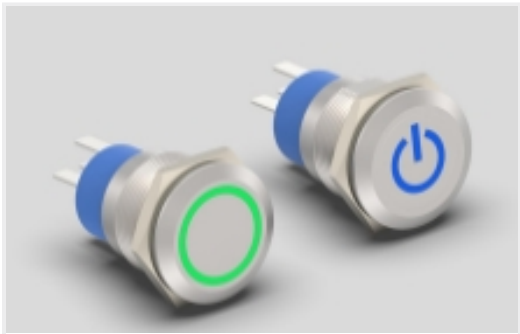

Anti-Vandal Switches(124)



Push Button Switches(124)

Customers Also Bought



TE Part #5-826629-0
50P AMPMODU II PIN HDR.

TE Part #SP44908X-19
44908X GSFC 311P18-08A7R6

TE Part #6-1625890-2
2W SM M/OX 5% 5K6

TE Part #183035-1
MINI MIC RCPT CONT.ACT.LP

TE Part #2-1437567-9
MPA106F=SWITCH P/B MOM SPDT

TE Part #2213771-5
AV22 DPM 3A NO LED

TE Part #CAT-T3437-T548
TMS-SCE Military Grade Sleeves

TE Part #F66623-000
DWP-125-1-KIT3-REFILL

TE Part #282108-1
AMP SUPERSEAL 1.5 SERIES 6P CA

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_5-2213772-3_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_5-2213772-3_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_5-2213772-3_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

ALCOSWITCH Anti-Vandal Switch

English

Agency Approvals



[UL Report](#)

English