


For punched or drilled metal sheets : OP1503

Edge protection grommets natural


Article number: 633-55039

 Add to watchlist



 Images (1)

 Downloads

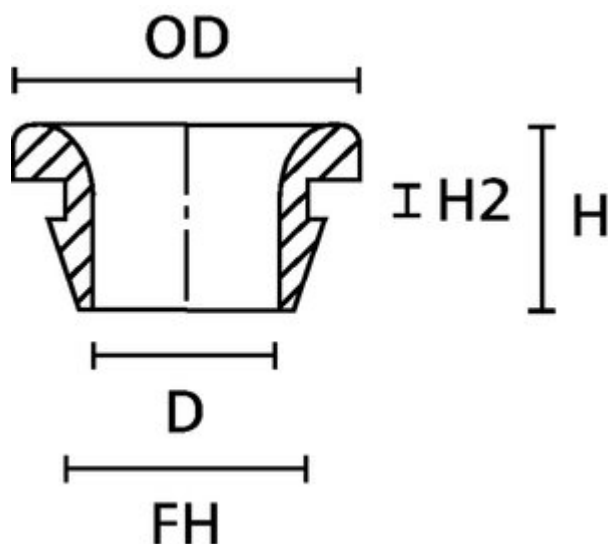

Features

- Protects cables from sharp edges
- Provides additional strain relief
- Flexible and easy to apply
- High resistance to chemicals and environmental influences

CONTACT 

Certifications & Approvals

RoHS 

Application

Edge protection grommets are used wherever cable and wires are routed through apertures. HellermannTyton grommets offer excellent mechanical protection.

More products in this product group

For punched or drilled metal sheets >



Base Data

Cable \emptyset max	6.4 mm
Cable \emptyset min	5.4 mm
Colour	Natural (NA)
Pack Cont.	2000 pcs.
Package Content in	pcs.
PART DESCRIPTION	OP1503-PE-NA
Product Family	Edge protection grommets
Product Group	For punched or drilled metal sheets
Short Description	Edge protection grommets natural
Variant	Open

Product Dimensions

Bundle \emptyset max.	9.6 mm
Diameter (D)	5.4 mm
for Hole \emptyset (FH)	6.7 mm
Height (H)	5.0 mm
Height (H2)	1.0 mm
Outside \emptyset (OD)	9.6 mm
Shore Hardness A	nom. 45

Material and Specifications

ELV compliant (Article 4 - 2)	YES
Flammability	UL 94 HB
Hazardous good	No
Material	Polyethylene (PE)
Operating Temperature - °C	-10 °C to +70 °C
Specifications	 Contact 

Waterproof No

Logistics and Packaging



More Information



ETIM 7.0 Key EC000879

Similar products



HV1305
633-03050
For apertures



HV1203
633-02030
Edge protection grommets



HV1608
633-06088
For apertures



HV1101
633-01010
For punched or drilled metal sheets



HV1201
633-02010
Edge protection grommets



HV1204
633-02040
For punched or drilled metal sheets



Show all

© HellermannTyton 2022

Contact