

RACON, square plunger 14 mm, L 4.8 mm



fields of application

- > Measurement-control-regulation
- > Mechanical and system engineering
- > Automotive
- > Signalling systems
- > Vehicle construction
- > Handheld terminals

description

The wide selection of standard plungers in different shapes and colors guarantees a versatile range of applications for the RACON tactile switch.

technical data

> general

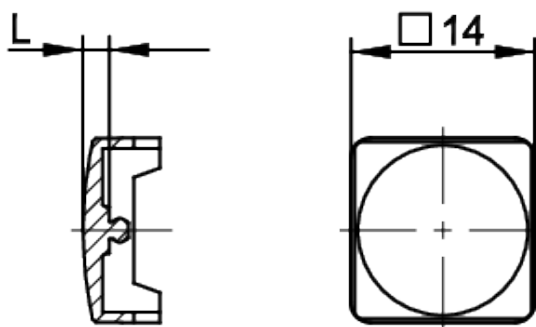
Color	white
Collar shape	square
illuminated	No
Packaging unit	500 pcs.
net weight	0.4 g
MOQ order	1,000 pcs.
RoHS compliant	Yes
REACH compliant	Yes
Component material	Plastic

direct links

- > [RAFI eCatalog](#)

> mounting diameters

Outside dimension, length	8.65 mm
Outside dimension, width	14 mm
Outside dimension, height	14 mm
Plunger length L	4.8 mm
Support height A	4.9 mm
Total height GH	9.7 mm

drawings**Dimensioned drawing****System drawing**