


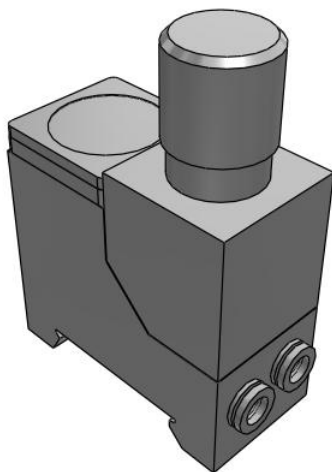


## ARM11B, Regulator Block, Individual Supply Type

### ARM11BB1-R08-A1

Datasheet

### General series information

 
- Regulator block, individual supply type
- IN/OUT fittings: straight & elbow (metric & inch)
- IN/OUT piping: bottom, top
- Handle position: top, bottom, front
- Accessories: pressure gauge
- Options: 0.35MPa setting, non-relieving, oil free



### Standard specifications

|                                               |                                        |
|-----------------------------------------------|----------------------------------------|
| Handle Position                               | B (Front)                              |
| Piping                                        | 1 (IN/OUT: Bottom)                     |
| Fitting                                       | 08 (IN: Straight Ø6, OUT: Straight Ø6) |
| Accessory                                     | A (Pressure Gauge)                     |
| Option                                        | 1 (0.35 MPa)                           |
| Unit                                          | Name Plate, Pressure Gauge MPa         |
| Digital Pressure Switch Output Specifications | None                                   |
| Maximum temperature of pressure medium        | 60 °C                                  |
| Minimum temperature of pressure medium        | -5 °C (with no freezing)               |
| Maximum operating pressure                    | 1.0 MPa                                |
| Proof pressure                                | 1.5 MPa                                |
| Set pressure range                            | 0.05 - 0.35 MPa                        |
| Applicable fluid                              | Air                                    |
| Regulator construction                        | Direct acting                          |
| Working principle                             | Piston type                            |
| Relief mechanism                              | Relieving type                         |
| Weight                                        | 0.140 Kg                               |

Dimensions

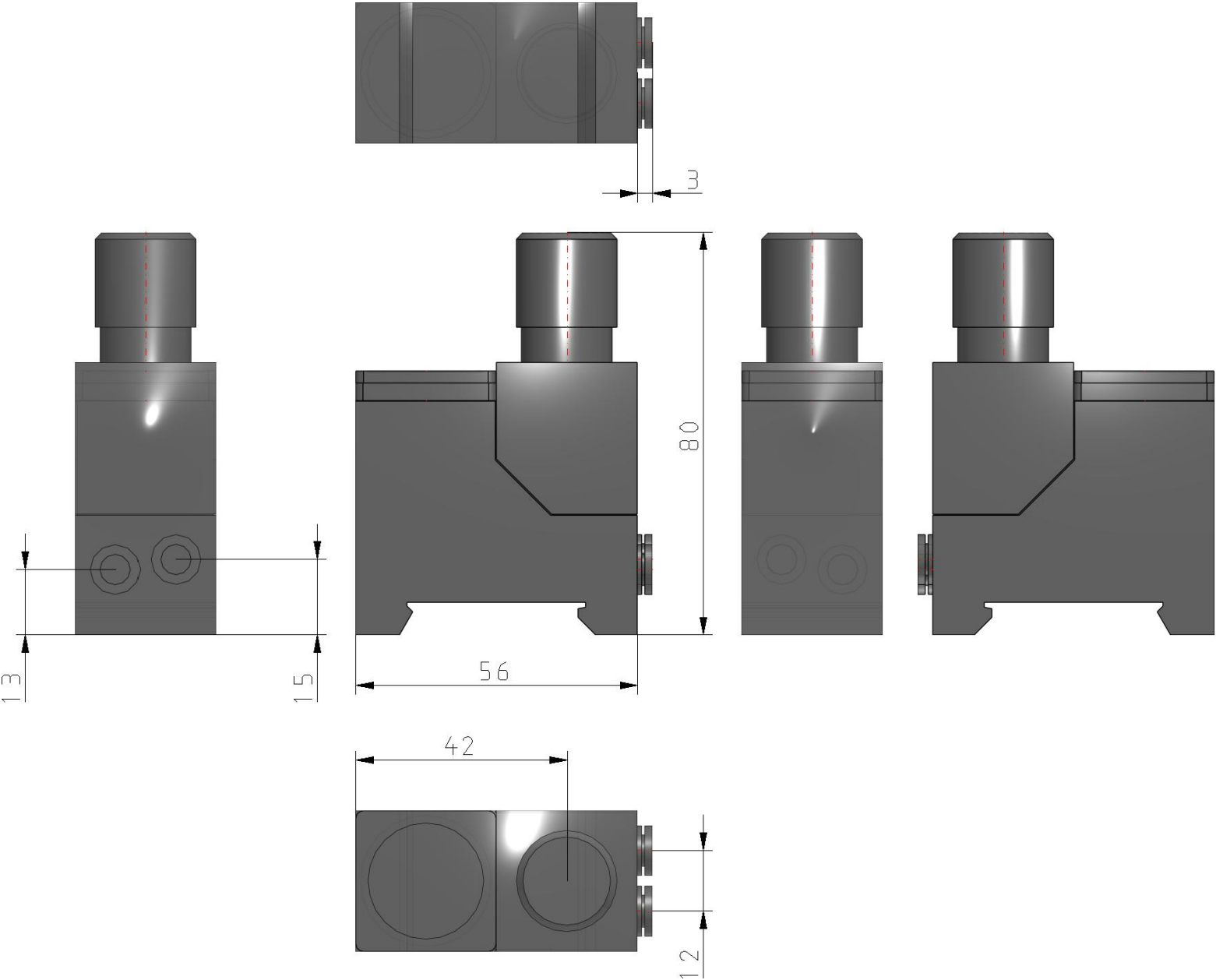

## Additional information

Catalogue

[ARM10-11\\_EU.pdf](#)

Operation manuals

[arm10\\_11\\_op\\_man\\_ar\\_-omg0039-a.pdf](#)