


Data sheet Product ISQ 06


 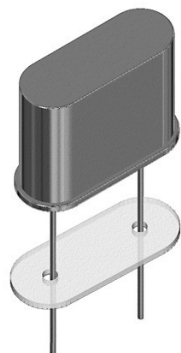


Sockets>Sockets for crystal oscillators
 Insulators for crystal mounts; * = self retaining

Features

version:	standard, punched
type:	insulators
case design:	• HC-18/U • HC-49/U • HC-43/U
dielectric strength:	9 kV
name of foil:	MYLAR
heat resistance:	250°C
material thickness:	0.127 mm

Technical Drawing

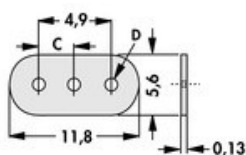

C: 2.4 mm

D: 0.71 mm