


TSI Code: 403422984

Price*: 80.00 GBP

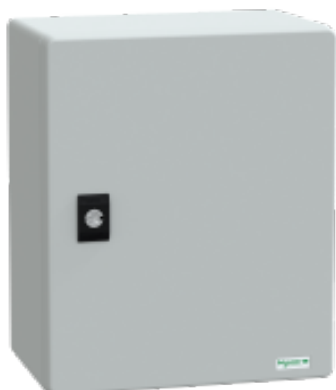

Main

Range	Thalassa
Product name	Thalassa PLM
Device short name	PLM
Device application	Multi-purpose
Product or component type	Compact enclosure
Enclosure nominal height	308 Mm
Enclosure nominal width	255 Mm
Enclosure nominal depth	160 Mm
Enclosure mounting	Wall mounted
Device composition	1 body 1 door 1 lock
Door type	Plain
Lock type	3 mm double-bar lock

Complementary

Number of locks	1
Mounting plate description	Without mounting plate
Accessibility for operation	Front
Removable parts	Door by hinges
Material	Polyester reinforced with fibreglass
Colour	Grey (RAL 7035)
Standards	IEC 62208 NEMA classification 13 NEMA classification 4X
Product certifications	UL
Electrical insulation class	Class II

Environment

IP degree of protection	IP66 conforming to IEC 60529
IK degree of protection	IK10 conforming to IEC 62262
Fire resistance	960 °C conforming to IEC 62208
Ambient air temperature for operation	-40...80 °C

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	3.414 Kg
Package 1 Height	18.5 Cm
Package 1 width	26.5 Cm
Package 1 Length	32.5 Cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------

Product Life Status : **Commercialised**